

Rocker Switches

ALPS SDDJF SERIES ROCKER POWER SWITCHES

DIMENSIONS: in.

Specifications:


- High capacity switch for TVs and other electronic devices supports regular 8A current and 128A inrush current
- Highly robust structure for rapid open/close operation (1m/sec.)

Applications:

- Flat panel TVs (LCD, plasma, displays) and monitors

For quantities of 1250 and up, call for quote.

MOUSER STOCK NO.	ALPS Part No.	Fig.	Function	Terminal	Price Each			
					1	50	100	500
Slim type 5.2mm body width								
688-SDDJF1A100	SDDJF1A100	A	SPST (ON) OFF	Quick Connect	2.28	1.83	1.74	1.55
16A 250V AC rating (for Photocopiers and Printers)								
688-SDDJF30100	SDDJF30100	B	DPST (ON)OFF	Quick Connect	3.53	3.20	2.84	2.55
688-SDDJF30200	SDDJF30200	B	DPST (ON)OFF	Quick Connect	3.53	3.20	2.84	2.55
688-SDDJF31000	SDDJF31000	C	DPST (ON)OFF	Quick Connect	4.29	3.88	3.48	3.11
688-SDDJF31100	SDDJF31100	C	DPST (ON)OFF	Quick Connect	4.29	3.88	3.48	3.11

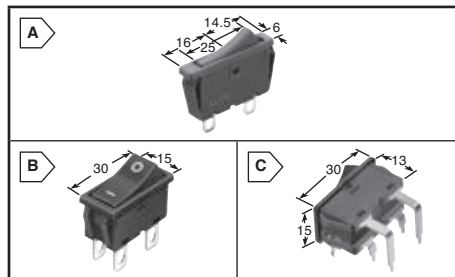


APEM APPLIANCE STYLE ROCKER SWITCHES

DIMENSIONS: in.

For quantities of 1000 and up, call for quote.

MOUSER STOCK NO.	Apem Part No.	Fig.	Function	Terminal	Price Each			
					1	25	100	500
642-FMC12A220	FMC12A220	A	SPST On-Off	Solder	1.27	1.22	1.09	1.00
642-FMC32A220	FMC32A220	A	SPST Off-(On)	Solder	2.64	2.24	2.13	1.99
642-FMC62A220	FMC62A220	A	SPDT On-On	Solder	1.58	1.51	1.32	1.23
642-FML18A276A0	FML18A276A0	A	SPST On-Off Illum. Red	Quick-connect	5.20	4.64	3.99	3.00
642-FMC92A220	FMC92A220	A	SPDT On Off On	PC	1.72	1.63	1.45	1.34
642-AS36S010010	AS36S010010	B	SPDT On-On	Solder	3.99	3.78	3.37	2.44
642-AS39S010010	AS39S010010	B	SPDT On-Off-On	Solder	3.30	2.99	2.72	2.32
642-AS37S010010	AS37S010010	B	SPDT (On)-Off-(On)	Solder	3.79	3.45	3.12	2.67
642-AS36P0	AS36P0	B	SPDT On-On	PC	2.88	2.61	2.36	2.04
642-AS39P0	AS39P0	B	SPDT On-Off-On	PC	3.05	2.85	2.56	2.23

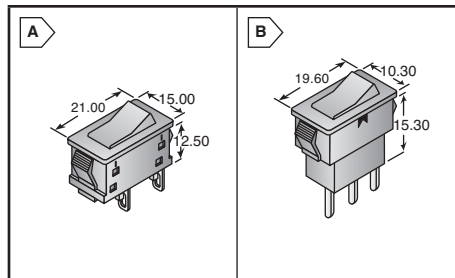


APEM POWER ROCKER SWITCHES

DIMENSIONS: in.

For quantities of 1000 and up, call for quote.

MOUSER STOCK NO.	Apem Part No.	Function	Price Each			
			1	25	100	500
Non-Illuminated						
642-KG312A2XXA21	KG312A2XXA21	SPST On-Off	7.85	7.07	6.67	6.00
642-KG362A2XXA21	KG362A2XXA21	SPDT On-On	12.20	10.70	9.70	8.65
642-KG372A2XXA21	KG372A2XXA21	SPDT (On) -Off-(On)	11.67	10.50	9.92	8.91
642-KG412A2XXA21	KG412A2XXA21	DPST On-Off	8.89	8.45	7.99	7.56
642-KG462A2XXA21	KG462A2XXA21	DPDT On-On	10.93	9.85	9.29	8.20

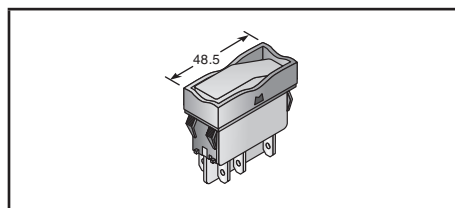

V SERIES: CONTURA SEALED ROCKER SWITCHES



DIMENSIONS: in.

Specifications:


- IP66/IP68 certified
- Meet UL1500/ISO8846 for ignition protection
- Temperature range: 40°C to +85°C

- Rating: 20A @ 12VDC
- Termination: 10 terminals, .250 QC without barriers

Flexibility of options with interchangeable actuators (sold separately below)

For quantities of 250 and up, call for quote.

MOUSER STOCK NO.	Carling Technologies Part No.	Fig.	Contact Form	Circuit	Price Each			
					1	25	50	100
Switch Body Only, No Lamps								
691-V2D2S00B	V2D2S00B-00000-000	A	SPST	(ON)-OFF	4.52	3.86	3.55	3.39
Actuators for Switches With No Lamps or LEDs								
691-VVAZC	VVAZC00-000	B	Black, hard, raised bumps each end		1.44	1.36	1.19	1.01
691-VVAZB	VVAZB00-000	B	Black, soft, raised bumps each end		1.69	1.44	1.31	1.27
Switch Body Only With 1 12V Amber LED and 1 12V Superbright Green LED								
691-V1D2GHNB	V1D2GHNB-00000-000	A	SPST	ON-OFF	9.60	8.20	7.71	7.21
691-V2D2GHNB	V2D2GHNB-00000-000	A	SPST	(ON)-OFF	10.10	8.63	8.11	7.59
691-VGD2GHNB	VGD2GHNB-00000-000	A	SPDT	OFF-ON-ON	13.18	11.26	10.51	9.90
691-V4D2GHNB	V4D2GHNB-00000-000	A	SPST	ON-ON	10.24	8.75	8.23	7.70
691-V6D2GHNB	V6D2GHNB-00000-000	A	SPDT	ON-OFF-ON	10.24	8.75	8.23	7.70
691-VED2GHNB	VED2GHNB-00000-000	A	SPDT	ON-ON-ON	14.14	12.08	11.27	10.62
691-V8D2GHNB	V8D2UHNB-00000-000	A	SPDT	(ON)-OFF-(ON)	9.07	7.75	7.07	6.82
691-VLD2GHNB	VLD2GHNB-00000-000	A	DPDT	(ON)-OFF-(ON)	11.34	9.69	8.78	8.52
Actuators for Switches With LEDs								
691-VVAAC	VVAAC00-000	C	Contura II, Black with white square lens, white bar		1.05	.90	.86	.79
691-VVEAC	VVEAC00-000	D	Contura IV, Black with white dual round lenses		1.71	1.47	1.36	1.15
691-VVFAC	VVFAC00-000	E	Contura IV, Black with white dual round lenses		1.17	1.11	1.06	.95
691-VVGAC	VVGAC00-000	F	Contura V, Black with white dual round lenses		1.30	1.23	1.08	.92
Switch Body Only With 1 12V Incandescent Lamp								
691-V1D2B60B	V1D2B60B-00000-000	A	SPST	ON-OFF	5.70	4.87	4.52	4.29
691-V8D2B60B	V8D2B60B-00000-000	A	SPDT	(ON)-OFF-(ON)	6.99	5.98	5.55	5.25
Switch Body Only With 2 12V Incandescent Lamps								
691-V6D2D66B	V6D2D66B-00000-000	A	SPDT	ON-OFF-ON	8.04	6.87	6.42	6.04
Actuators for Switches With Incandescent Lamps								
691-VVCMC	VVCMC00-000	G	Contura III, Red bar lens one end		1.05	.90	.86	.79
691-VVCNC	VVCNC00-000	H	Contura III, 2 red bar lenses, 1 each end		1.05	.90	.86	.79
691-VVENC	VVENC00-000	I	Contura IV, 2 red bar lenses, 1 each end		1.71	1.47	1.36	1.15
691-VVFNC	VVFNC00-000	J	Contura IV, 2 red bar lenses, 1 each end		1.76	1.65	1.45	1.24
Tools and Accessories for Contura Switches								
691-VRT	VRT	--	Actuator removal tool		2.65	2.27	2.08	1.76
691-VPS-01	VPS-01	--	Panel seal		.74	.63	.58	.49
691-VC1-01	VC1-01	--	10 terminal connector		.92	.88	.84	.76
691-VH2-01	VH2-01	--	Hole plug		1.11	.95	.90	.86
691-VM3-01	VM3-01	--	3-gang mounting bracket		3.32	2.84	2.68	2.58

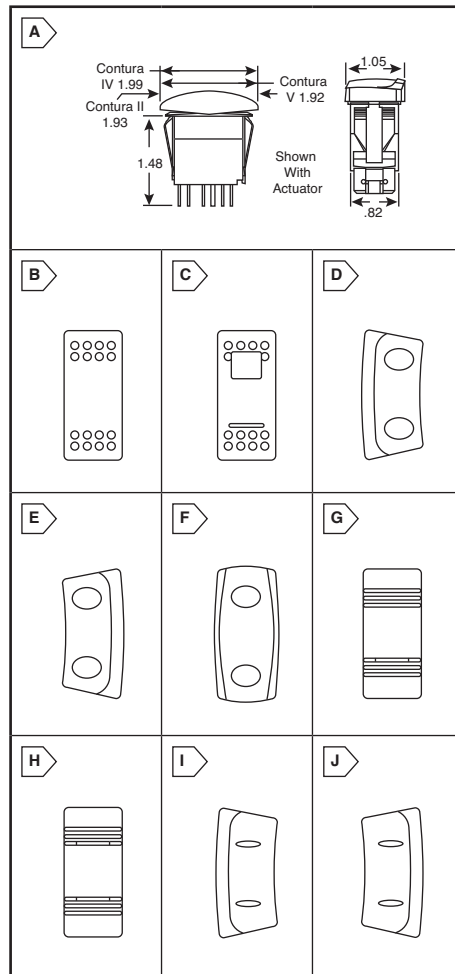

Rocker Switches