


Pliers, Cutters and Fuse Pullers



COOPER Hand Tools PLIERS

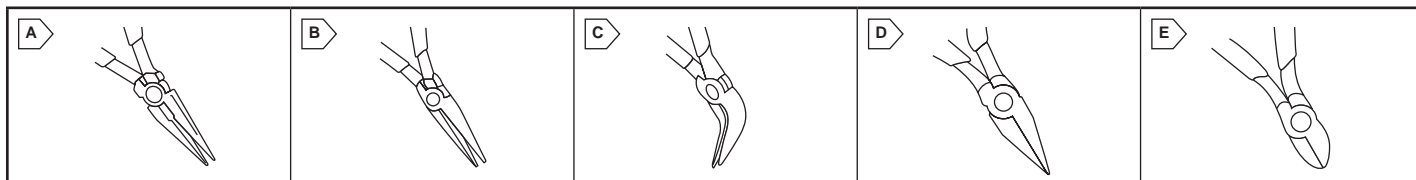

- Lightweight, miniature plier line
- Choice of oval, tapered, relieved, and angled head
- Full flush or semi-flush cutting edges
- Needle nose styles include long, short, curved, flat, and round to handle most forming, looping, twisting, insertion, and pickup jobs

- Forged from high quality alloy steel for maximum strength and durability.
- Precision ground to close tolerances, individually finished and tested to ensure exact fit of jaws
- Polished heads with gun metal handles
- Made in the U. S. A.


Xcelite® Diagonal Cutting Pliers and Electronic Shears

† Not ESD Safe

For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Fig.	Size (in.)	Description	Price Each
Mfr.	Mfr. Part No.				
578—SN54		A	5	Long nose with side cutter, finely scored jaws	18.52
578—SN55		A	5 1/2	Long nose with side cutter, finely scored jaws	18.51
578—L4		B	4	Long nose subminiature, very fine point	15.02
578—LN54		B	5	Long nose finely scored jaws	17.00
578—LN55		B	5 1/2	Long nose finely scored jaws	16.94
578—CN54G		C	5	Long curved nose (approx 60°), smooth jaws	18.52
578—NN54		B	5	Needle nose finely scored jaws	19.40
578—NN54G		B	5	Needle nose smooth jaws, slightly rounded edges	19.55
578—RN54		B	4 1/2	Round nose smooth jaws, for forming loops in wire	18.19
578—NN7776		B	6	Extra long needle nose	18.49
578—DN54G		D	5	Flat nose smooth jaws	18.90
578—LN54G		B	5	Thin long nose smooth jaws	16.62

MOUSER STOCK NO.		Fig.	Size (in.)	Description	Price Each	
Mfr.	Mfr. Part No.				1	5
578—SN54		A	5	Long nose with side cutter, finely scored jaws	18.52	
578—SN55		A	5 1/2	Long nose with side cutter, finely scored jaws	18.51	
578—L4		B	4	Long nose subminiature, very fine point	15.02	
578—LN54		B	5	Long nose finely scored jaws	17.00	
578—LN55		B	5 1/2	Long nose finely scored jaws	16.94	
578—CN54G		C	5	Long curved nose (approx 60°), smooth jaws	18.52	
578—NN54		B	5	Needle nose finely scored jaws	19.40	
578—NN54G		B	5	Needle nose smooth jaws, slightly rounded edges	19.55	
578—RN54		B	4 1/2	Round nose smooth jaws, for forming loops in wire	18.19	
578—NN7776		B	6	Extra long needle nose	18.49	
† 578—DN54G		D	5	Flat nose smooth jaws	18.90	
578—LN54G		B	5	Thin long nose smooth jaws	16.62	
578—MS54J		E	4	Oval head, flush cut	16.97	

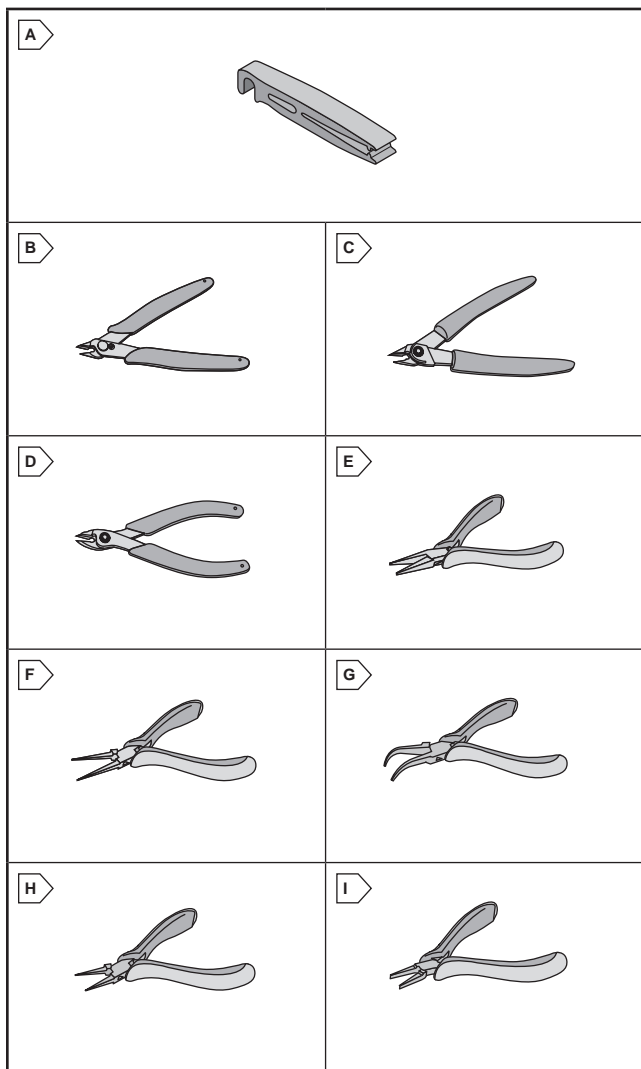

/// eagle FUSE PULLERS

plastic devices

For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Fig.	Description	Price Each			
Mfr.	Mfr. Part No.			1	5	10	20
441—EPD213		A	Dual Fuse Puller	.48	.39	.35	.31

PLATO PLATOSHEAR LEAD CUTTERS

- Effortless shearing action, comfort, light weight, and safety for electronics lead cutting
- Platoshear requires 50% less operator effort and has a longer cutting life than conventional cutters because it shears rather than bites
- Cushioned handles provide daylong comfort
- Thin profile designed for those hard-to-get-at areas in electronic assembly where conventional cutters can't reach
- Made in the U.S.A

For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Fig.	Description	Price Each	
Mfr.	Mfr. Part No.			1	5
577—170		B	General purpose Lead Cutter	5.62	
577—170SD		C	Static Dissipative Lead cutter	10.63	
577—175SD		C	Static Dissipative Lead cutter With Safety Guard	13.15	
577—170LX		B	Ergonomic, ESD safe shear cutter	8.12	
577—175LX		C	Ergonomic, ESD safe shear cutter with safety guard	10.91	
577—175		B	Lead Cutter With Safety Guard	8.06	
577—1755		D	Wire/Cable Cutter	16.93	

Witza ESD SAFE PLIERS

- Cutting edges are induction hardened at a hardness of Approx. 64°HRC.
- Two component non-slip soft grip handle
- ESD Safe Dissipative



For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Fig.	Description	Length	Price Each	
Mfr.	Mfr. Part No.				1	5
596—32742		E	Pliers, Short Snipe Nose Straight, Serrated Jaws	20mm	41.55	30.11
596—32746		F	Pliers, Long Needle Nose, Straight, Serr. Jaws	45mm	47.34	34.33
596—32748		G	Pliers, Needle Nose, Bent 90°, Smooth Jaws	45mm	46.18	33.49
596—32750		H	Pliers, Short Round Nose, Smooth Jaws	120mm	41.55	30.11
596—32752		I	Pliers, Short Flat Nose, Smooth Jaws	120mm	41.55	30.11