


# SCHURTER Fuseholders



RoHS Compliant This product is RoHS compliant.

ELECTRONIC COMPONENTS

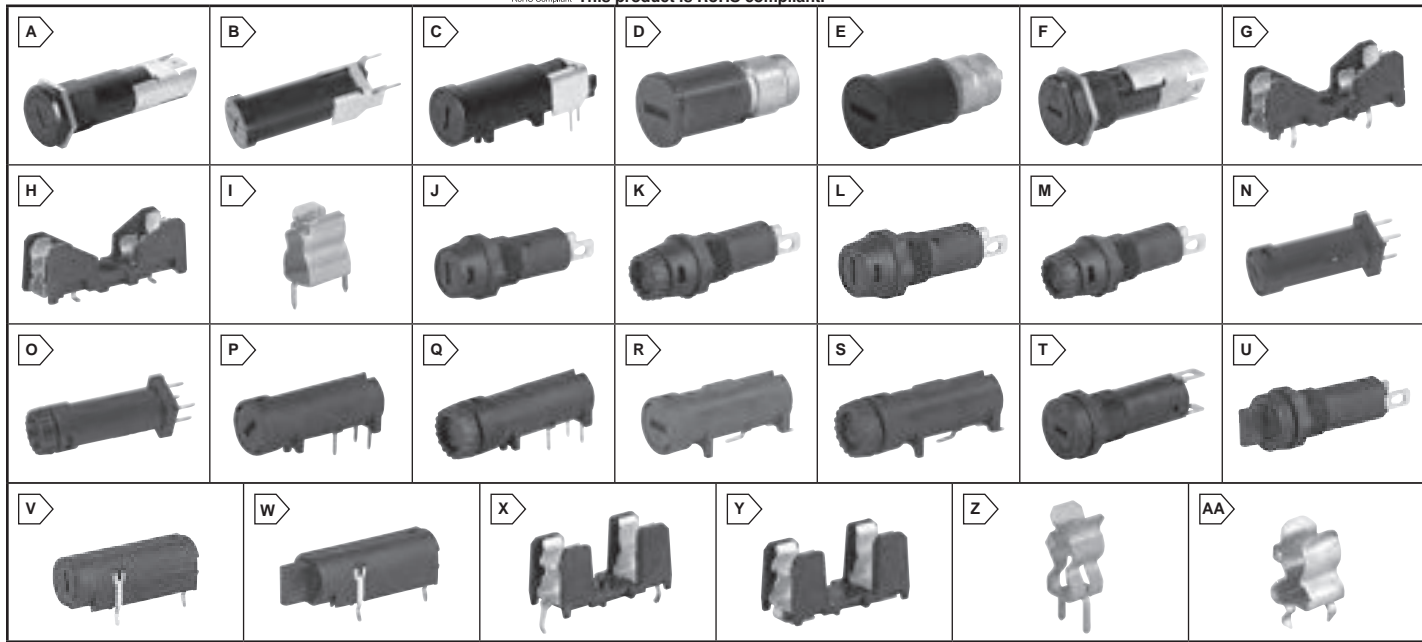

Fuses & Fuse Holders Schurter

## FUL, FUA, FUP HIGH CURRENT FUSEHOLDERS

500VAC, 16A

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Schurter Part No.	Fig.	Terminals	Price Each			
				1	50	100	500
693-0031.2307	0031.2307	A	solder	9.87	7.40	6.65	5.02
693-0031.2308	0031.2308	A	quick-connect	8.09	6.18	5.61	4.43
693-0031.2303	0031.2303	A	solder	6.45	5.86	5.38	4.61
693-0031.2304	0031.2304	A	quick-connect	5.22	4.74	4.35	3.95
693-0031.2550	0031.2550	B	PCB vertical	4.98	4.53	4.17	3.83
* 693-0031.2560	0031.2560	B	PCB vertical	9.11	8.28	7.60	7.08
† 693-0031.2570	0031.2570	B	PCB vertical	9.72	8.84	8.14	7.48
† 693-0031.2500	0031.2500	C	PCB horizontal	4.98	4.53	4.17	3.83
† 693-0031.2510	0031.2510	C	PCB horizontal	13.67	9.84	9.29	8.20
† 693-0031.2520	0031.2520	C	PCB horizontal	12.02	10.93	10.07	9.25

\*Complete with 5x20mm IP 40 carrier.

†Complete with 6.3x32mm IP 40 carrier.

## CARRIERS FOR FUL, FUA, FUP FUSEHOLDERS

500VAC, 30A

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Schurter Part No.	Fig.	Fuse Size	IP	Price Each			
					1	50	100	500
693-0031.2321	0031.2321	D	1/4x1-1/4"	40	5.03	4.11	3.77	3.42
* 693-0031.2322	0031.2322	E	5x20mm	67	4.90	4.49	4.14	4.07
693-0031.2323	0031.2323	D	5x20mm	40	8.97	6.67	5.99	4.54

\*For FUL SERIES only.

## FIZ HIGH CURRENT 5X20MM FUSEHOLDERS

250VAC, 16A

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Schurter Part No.	Fig.	Terminals	Price Each			
				1	50	100	500
693-0031.2203	0031.2203	F	solder	18.98	14.18	12.73	9.62
693-0031.2207	0031.2207	F	quick-connect	12.77	11.77	10.82	9.96
693-0031.2201	0031.2201	F	solder	20.43	15.23	13.71	10.36
693-0031.2205	0031.2205	F	quick-connect	9.99	9.42	8.99	8.77

\*IP 40 and IP 67 versions available.

## OGD 5X20MM FUSEHOLDERS

500VAC, 10A

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Schurter Part No.	Fig.	Terminals	Price Each			
				1	50	100	500
693-0031.8231	0031.8231	G	thru-hole	.85	.71	.68	.65
693-0031.8241	0031.8241	H	SMD	1.13	1.07	.99	.87

## OG DUAL SIZE PCB MOUNT FUSE CLIPS

600VAC, 10A

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Schurter Part No.	Fig.	Terminals	Price Each			
				1	50	100	500
* 693-0751.0099	0751.0099	I	tin-plated bronze	.39	.36	.315	.298
* 693-0751.0100	0751.0100	I	tin-plated brass	.40	.37	.325	.307
693-0751.0141	0751.0141	I	tin-plated bronze	.78	.59	.506	.385
693-0751.0142	0751.0142	I	tin-plated brass	.61	.47	.419	.311

\*With "kicked terminals."

## FPG1 5X20MM FUSEHOLDERS

250VAC, 10A

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Schurter Part No.	Fig.	Carrier Style	Terminals	Price Each			
					1	50	100	500
693-3101.0010	3101.0010	J	slotted	solder	2.07	1.62	1.55	1.44
693-3101.0210	3101.0210	J	slotted	quick-connect	3.78	3.43	3.15	2.91
693-3101.0015	3101.0015	K	fingerrip	solder	2.45	2.10	1.99	1.82
693-3101.0215	3101.0215	K	fingerrip	quick-connect	2.10	1.90	1.75	1.61
693-3101.0110	3101.0110	L	slotted	solder	3.88	3.45	3.10	2.93
693-3101.0310	3101.0310	L	slotted	quick-connect	3.40	3.09	2.84	2.62
693-3101.0115	3101.0115	M	fingerrip	solder	3.43	2.68	2.56	2.40
693-3101.0315	3101.0315	M	fingerrip	quick-connect	4.21	3.16	2.91	2.47

## FPG4, 5 AND 7 - 5X20MM FUSEHOLDERS

250VAC, 10A

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Schurter Part No.	Fig.	Carrier Style	Terminals	Price Each			
					1	50	100	500
693-3101.0040	3101.0040	N	slotted	thru-hole	2.07	1.62	1.55	1.44
693-3101.0045	3101.0045	O	fingerrip	thru-hole	2.18	1.87	1.77	1.62
693-3101.0050	3101.0050	P	slotted	thru-hole	2.07	1.62	1.55	1.44
693-3101.0055	3101.0055	Q	fingerrip	thru-hole	2.07	1.62	1.55	1.44
693-3101.0070	3101.0070	R	slotted	SMD	2.38	1.95	1.79	1.55
693-3101.0075	3101.0075	S	fingerrip	SMD	2.92	2.10	1.98	1.74

## FBS 5X20MM FUSEHOLDERS

250VAC, 10A

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Schurter Part No.	Fig.	Carrier Style	Terminals	Price Each			
					1	50	100	500
693-0031.3901	0031.3901	T	slotted	solder	3.52	3.17	2.88	2.19
693-0031.3903	0031.3903	T	slotted	quick-connect	3.10	2.82	2.60	2.39
693-0031.3911	0031.3911	U	fingerrip	solder	2.77	2.50	2.27	1.73
693-0031.3913	0031.3913	U	fingerrip	quick-connect	2.75	2.50	2.30	2.11
693-0031.3981	0031.3981	V	slotted	PCB	2.91	2.62	2.38	1.81
693-0031.3991	0031.3991	W	fingerrip	PCB	4.72	3.49	3.16	2.37

## OGN FUSEHOLDERS FOR 5X20MM FUSES

250VAC, 10A

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Schurter Part No.	Fig.	Carrier Style	Terminals	Price Each			
					1	50	100	500
693-0031.8201	0031.8201	X	22.5	thru-hole	.41	.338	.324	.315
693-0031.8211	0031.8211	X	25	thru-hole	.65	.51	.46	.35
693-0031.8221	0031.8221	Y	17	SMD	1.12	.814	.739	.546

## OG 5X20MM PCB MOUNT FUSE CLIPS

250VAC, 6.3A

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Schurter Part No.	Fig.	Carrier Style	Terminals	Price Each			
					1	50	100	500
693-0751.0052	0751.0052	Z	straight	bronze	.17	.15	.142	.118
693-0751.0062	0751.0062	Z	straight	brass	.10	.09	.08	.07
693-0751.0110	0751.0110	AA	kicked	bronze	.12	.10	.09	.08