

# OK INDUSTRIES Wire Wrap Tools, Strippers & Accessories



## JIC WIRE STRIPPER AND CUTTER

### Features:

- 6 3/4" and weight 4.5 ounces

MOUSER STOCK NO.	Fig.	Description	Price Each	
			1	5
801-JIC-1022	A	Wire Stripper and Cutter 10-20AWG	9.10	8.65
801-JIC-1626	A	Wire Stripper and Cutter 16-26AWG	9.10	8.65
801-JIC-2030	A	Wire Stripper and Cutter 20-30AWG	9.10	8.65

## UNIVERSAL CABLE STRIPPING TOOL AND COAXIAL CABLE STRIPPER TOOL

MOUSER STOCK NO.	Fig.	Description	13.25	13.25
801-UST-500	B	Universal Stripping Tool (59/6)	13.25	13.25
801-UST-100	C	Coax Stripping Tool RG59/6 and7/11	11.90	11.90

## CABLE STRIPPER AND KITS

MOUSER STOCK NO.	Fig.	Description	50.35	50.35
801-CST-1900	D	Round Cable Stripper	50.35	50.35
801-ND-631	E	Hollow Shaft Nut Driver Kit	42.90	40.76
801-TK-400	F	Splicer's Kit	27.25	27.25

## KSW WIRE WRAPPING WIRE ROLLS FOR CUT/STRIP/WRAP APPLICATIONS

- Low strip force KYNAR insulated wire for use with CSW bits and sleeves.

Replace the blank in part number with: **B** for Blue, **W** for White, **R** for Red, **Y** for Yellow, **BLK** for Black.

MOUSER STOCK NO.	OK Industries Part No.	Fig.	AWG Size	Insulation Dia. (in.)	100' Spool		1000' Spool	
					1	5	1	5
801-KSW24	KSW24_-0100	G	24	.030	27.90	27.90	-	-
801-KSW26	KSW26_-0100	G	26	.027	26.85	26.85	-	-
801-KSW28	KSW28_-0100	G	28	.0235	26.85	26.85	-	-
801-KSW30	KSW30_-0100	G	30	.0195	24.50	24.50	-	-
801-KSW30	KSW30_-1000	G	30	.0195	-	-	94.10	94.10

## KYNAR INSULATED, SILVER PLATED COPPER CONDUCTOR

Replace the blank in part number with: **B** for Blue, **W** for White, **R** for Red, **Y** for Yellow.

MOUSER STOCK NO.	Part No.	Fig.	AWG Size	Insulation Dia. (in.)	21.65	21.65	-	-
801-R24	R24_-0100	G	24	.030	21.65	21.65	-	-
801-R26	R26_-0100	G	26	.027	15.90	15.90	-	-
801-R28	R28_-0100	G	28	.0235	13.85	13.85	-	-
801-R30	R30_-0100	G	30	.0195	12.35	12.35	-	-
801-R30	R30_-1000	G	30	.0195	-	-	62.90	62.90

## PRE-CUT AND PRE-STRIPPED WIRE WRAPPING WIRE

- 50 pieces per package
- KYNAR insulated
- UUL listed
- Silver plated copper conductor

Replace the blank in part number with: **B** for Blue, **W** for White, **R** for Red, **Y** for Yellow.

MOUSER STOCK NO.	OK Industries Part No.	Fig.	Insulation Length	AWG Size	Price Each	
					1	5
801-30_-50-010	30_-50-010	H	1	30	8.65	8.65
801-30_-50-050	30_-50-050	H	5	30	9.65	9.65

## WIRE DISPENSER-WD-30 SERIES

- 30AWG Kynar wire wrapping wire
- Built-in Plunger cuts wire to desired length
- Built-in Stripper strips 1" of insulation
- Refillable

MOUSER STOCK NO.	OK Industries Part No.	Fig.	Description	Price Each	
				1	5
801-WD-30-B	WD-30-B	I	Dispenser with 50' of Blue wire	20.65	20.65
801-WD-30-Y	WD-30-Y	I	Dispenser with 50' of Yellow wire	20.65	20.65
801-WD-30-W	WD-30-W	I	Dispenser with 50' of White wire	20.65	20.65
801-WD-30-R	WD-30-R	I	Dispenser with 50' of Red wire	20.65	20.65
801-WD-30-TRI	WD-30-TRI	I	Dispenser with 50' each Blue, White and Red wire	34.00	34.00

### Replacement Rolls of Wire for WD-30 Series

MOUSER STOCK NO.	OK Industries Part No.	Fig.	Description	9.65	9.65
801-R-30B-0050	R-30B-0050	-	30AWG Blue 50' for WD-30-B	9.65	9.65
801-R-30Y-0050	R-30Y-0050	-	30AWG Yellow 50' for WD-30-Y	9.65	9.65
801-R-30W-0050	R-30W-0050	-	30AWG White 50' for WD-30-W	9.65	9.65
801-R-30R-0050	R-30R-0050	-	30AWG Red 50' for WD-30-R	9.65	9.65
801-R30-TRI	R-30-TRI	-	30AWG Red, White, Blue for WD-30-TRI	19.35	19.35

## ADJUSTABLE PRECISION WIRE STRIPPERS

A calibrated wire stop can be adjusted for the desired insulation strip length. In a single motion, the operator squeezes and pulls the tool. This action engages four specially hardened blades to cleanly cut wire insulation while the pulling motion breaks the insulation/conductor bond.

- Adjustable to six wire gauges:
  - ST-450 26 to 36AWG
  - ST-500 20 to 30AWG
  - ST-500ESD 20 to 30AWG
  - ST-550 18 to 28AWG
- Calibrated Wire Stop adjustable to 2"(50.8mm)
- Clean, precise strip of any insulation type
- Lightweight-weighs 1oz.
- Blade is hardened steel (RC58)
- Dimensions 3.9"x1.6"x0.6" (90mmx42mmx14mm)


MOUSER STOCK NO.	OK Industries Part No.	Fig.	Description	Price Each	
				1	5
801-ST-450	ST-450	J	Wire Gauge 26-36AWG	41.60	41.60
801-ST-500	ST-500	J	Wire Gauge 20-30AWG	34.60	34.60
801-ST-500ESD	ST-500ESD	J	Wire Gauge 20-30AWG	49.90	49.90
801-ST-550	ST-550	J	Wire Gauge 18-28AWG	34.60	34.60

## WIRE WRAPPING BITS AND SLEEVES

Fully compatible with any make or model wire wrapping tool.

\* Recommended for .025" square terminals on .100" centers.

Bits					Sleeves									
MOUSER STOCK NO.	OK Industries Part No.	Fig.	AWG	Wrap	Price Each	MOUSER STOCK NO.	OK Industries Part No.	Fig.	Maximum Insulation Dia.	Minimum Term Dia.	Maximum Term Dia.	Terminal Hole Depth (in.)	Terminal Hole Dia. (in.)	Price Each
801-KB224	KB224	N	22-24	Reg.	44.50	801-P2224	P2224	O	-	.054	.073	.807	.075	20.81
* 801-WB26SM	WB26SM	N	26	Mod.	50.10	801-P26LN	P26LN	O	.031	.023	.038	.750	.040	37.26
* 801-WB3032M	WB3032M	N	30-32	Mod.	50.10	801-P3032	P3032	O	.027	.034	.038	.750	.040	37.26

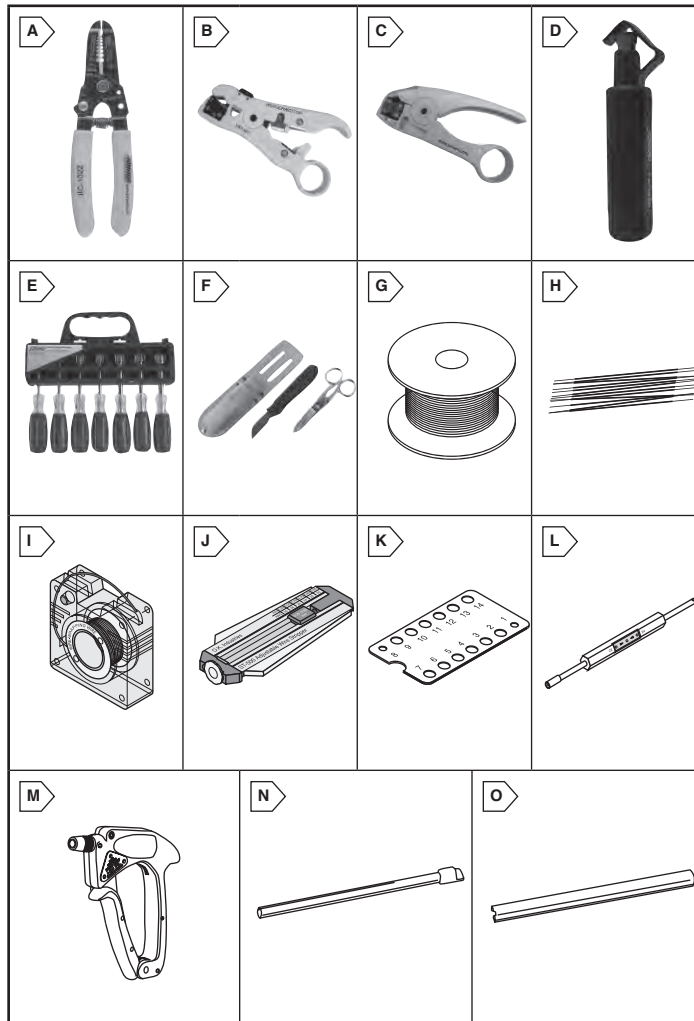

## SOCKET-WRAP I.D.

Used to identify pin numbers on wire wrapping sockets. These unique items greatly simplify both initial wire wrapping and subsequent troubleshooting or repair.

MOUSER STOCK NO.	OK Industries Part No.	Fig.	Pins	Row Spacing	Quantity/Package	Price Each
801-ID-8-100	ID-8-100	K	8	.3"	100	41.90
801-ID-18-50	ID-18-50	K	18	.3"	50	41.90
801-ID-24-50	ID-24-50	K	24	.6"	50	41.90
801-ID-28-50	ID-28-50	K	28	.6"	50	41.90
801-ID-96-25	ID-96-25	K	96	.3"	25	41.90

## HAND WRAPPING, STRIPPING AND UNWRAPPING TOOLS

Each WSU tool wraps, unwraps and even strips the appropriate wire diameter with a unique built-in stripper blade. Ideal for bench use or tool kit in all service and repair applications. In addition to versatility, convenience, and reliability, the WSU Series offers exceptional value.

MOUSER STOCK NO.	OK Industries Part No.	Fig.	AWG Size	Term. Hole Depth (in.)	Term. Hole Dia. (in.)	Outside Dia. (in.)	Square Post (in.)	Price Each
801-WSU-2224	WSU-2224	L	22-24	1.50	.075	.213	.045	43.60
801-WSU-24M	WSU-24M	L	24	1.50	.075	.213	.045	43.60
801-WSU-26M	WSU-26M	L	26	1.50	.075	.213	.045	43.60
801-WSU-30	WSU-30	L	30	1.50	.036	.125	.025	30.50
801-WSU-30M	WSU-30M	L	30	1.50	.036	.125	.025	30.50

## MANUAL WIRE WRAPPING TOOLS

Accommodates wire sizes from 22AWG through 32AWG. Offered in aluminum, insulated aluminum, and lexan, an industrial grade plastic.

MOUSER STOCK NO.	OK Industries Part No.	Fig.	Description	Price Each
801-G100R3278	G100/R3278	M	Aluminum	129.87
801-G100R3278INS	G100/R3278INS	M	Insulated Aluminum	133.05

