


PHOENIX CONTACT Terminal Blocks



RoHS Compliant This page of product is RoHS compliant.

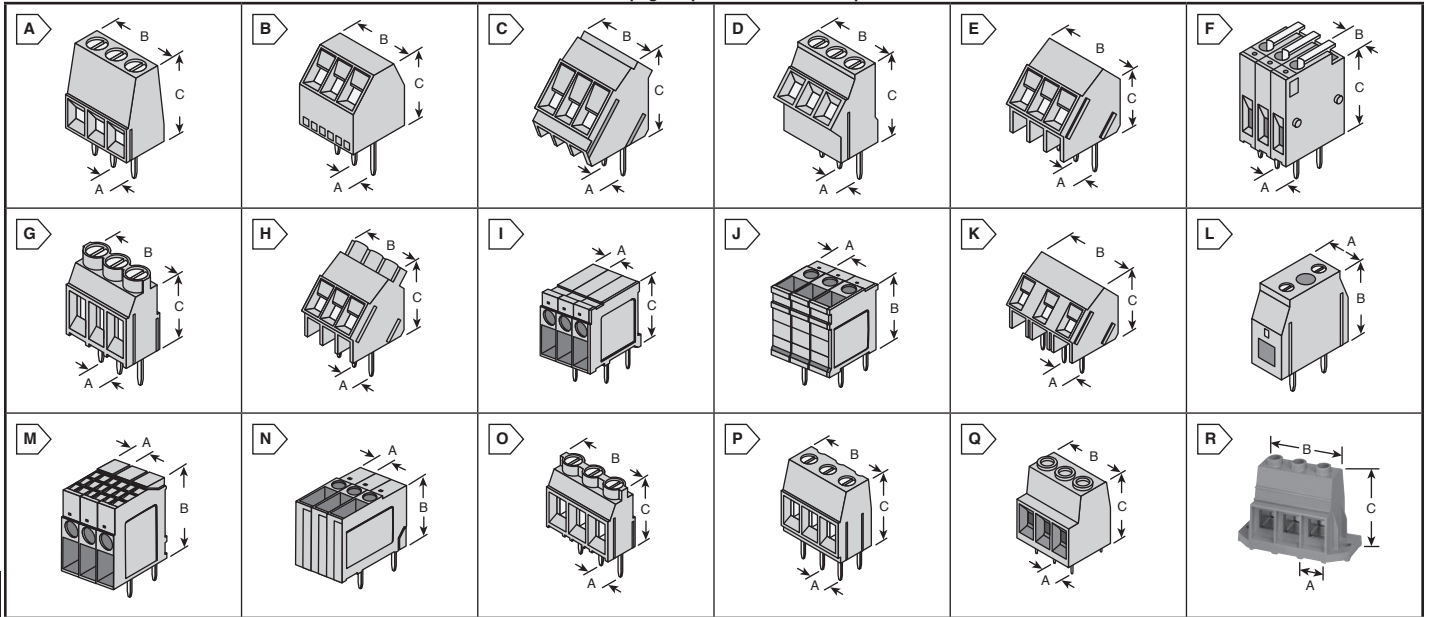

ONE PIECE DESIGN WITH SCREW CLAMP, SINGLE LEVEL, THROUGH-HOLE SOLDER MOUNTING TERMINATION



Phoenix Contact Terminal Blocks

For quantities greater than listed, call for quote.

For quantities greater than listed, call for quote.

MOUSER STOCK NO. Mfr./Mfr. Part No.	Fig.	Phoenix Type	Pos.	Dimensions: mm			Price Each		
				A	B	C	1	10	50
300V @ 10A, 30-14AWG, Green Color									
651-1729128	A	MKDSN 1.5/2-5.08	2	5.08	10.16	10	.96	.92	.88
651-1729131	A	MKDSN 1.5/3-5.08	3	5.08	15.24	10	1.42	1.36	1.30
651-1729144	A	MKDSN 1.5/4-5.08	4	5.08	20.32	10	1.92	1.83	1.76
651-1729157	A	MKDSN 1.5/5-5.08	5	5.08	25.4	10	2.40	2.29	2.20
651-1729160	A	MKDSN 1.5/6-5.08	6	5.08	30.48	10	2.72	2.64	2.56
651-1729173	A	MKDSN 1.5/7-5.08	7	5.08	35.56	10	3.15	3.05	2.97
651-1729186	A	MKDSN 1.5/8-5.08	8	5.08	40.64	10	3.62	3.50	3.41
651-1729199	A	MKDSN 1.5/9-5.08	9	5.08	45.72	10	4.08	3.94	3.84
651-1729209	A	MKDSN 1.5/10-5.08	10	5.08	50.8	10	4.54	4.40	4.28
651-1729212	A	MKDSN 1.5/11-5.08	11	5.08	55.88	10	4.86	4.73	4.42
651-1869225	A	MKDSN 1.5/12-5.08	12	5.08	60.96	10	5.26	5.12	4.79
300V @ 10A, 30-14AWG, Green Color									
651-1869211	B	SMKDSN 1.5/2-5.08	2	5.08	11.16	11	1.14	1.10	1.05
651-1869224	B	SMKDSN 1.5/3-5.08	3	5.08	16.24	11	1.69	1.61	1.55
651-1869237	B	SMKDSN 1.5/4-5.08	4	5.08	21.32	11	2.23	2.13	2.04
651-1869240	B	SMKDSN 1.5/5-5.08	5	5.08	26.4	11	2.67	2.58	2.51
651-1869253	B	SMKDSN 1.5/6-5.08	6	5.08	31.48	11	3.21	3.11	3.02
651-1869266	B	SMKDSN 1.5/7-5.08	7	5.08	36.56	11	3.73	3.61	3.52
651-1869279	B	SMKDSN 1.5/8-5.08	8	5.08	41.64	11	4.27	4.13	4.02
651-1869282	B	SMKDSN 1.5/9-5.08	9	5.08	46.72	11	4.79	4.64	4.51
651-1869295	B	SMKDSN 1.5/10-5.08	10	5.08	51.8	11	5.34	5.17	5.02
300V @ 10A, 30-14AWG, Green Color									
651-1715721	A	MKDS 1.5/2-5.08	2	5.08	10.16	13.8	1.18	1.13	1.08
651-1715734	A	MKDS 1.5/3-5.08	3	5.08	15.24	13.8	1.71	1.64	1.57
651-1715747	A	MKDS 1.5/4-5.08	4	5.08	20.32	13.8	2.27	2.17	2.07
651-1715789	A	MKDS 1.5/8-5.08	8	5.08	40.64	13.8	4.20	4.08	3.82
651-1715802	A	MKDS 1.5/10-5.08	10	5.08	50.8	13.8	5.24	5.10	4.77
651-1715828	A	MKDS 1.5/12-5.08	12	5.08	60.96	13.8	6.29	6.12	5.72
300V @ 10A, 30-12AWG, Green Color									
651-1888687	A	MKDSN 2.5/2-5.08	2	5.08	10.16	15	1.02	.974	.932
651-1888690	A	MKDSN 2.5/3-5.08	3	5.08	15.24	15	1.54	1.48	1.41
651-1888700	A	MKDSN 2.5/4-5.08	4	5.08	20.32	15	2.02	1.94	1.85
300V @ 10A, 30-12AWG, Green Color									
651-1711725	A	MKDS 3/2-5.08	2	5.08	10.16	18	1.70	1.65	1.60
651-1711738	A	MKDS 3/3-5.08	3	5.08	15.24	18	2.56	2.48	2.41
300V @ 10A, 30-14AWG, Green Color									
651-1713723	C	SMKDS 3/2-5.08	2	5.08	10.16	18	1.97	1.91	1.86
651-1713736	C	SMKDS 3/3-5.08	3	5.08	15.24	18	2.96	2.87	2.79
300V @ 10A, 30-14AWG, Green Color									
651-1705469	D	SMKDS 2.5/2-5.08	2	5.08	10.16	19.4	1.69	1.64	1.54
651-1705472	D	SMKDS 2.5/3-5.08	3	5.08	15.24	19.4	2.57	2.50	2.34
300V @ 10A, 30-14AWG, Green Color									
651-1733570	E	SMKDS 1.5/2-5.08	2	5.08	10.16	15.3	1.21	1.16	1.11
651-1733583	E	SMKDS 1.5/3-5.08	3	5.08	15.24	15.3	1.81	1.73	1.66
651-1733596	E	SMKDS 1.5/4-5.08	4	5.08	20.32	15.3	2.40	2.29	2.20
651-1733606	E	SMKDS 1.5/5-5.08	5	5.08	25.4	15.3	2.99	2.85	2.73
651-1733619	E	SMKDS 1.5/6-5.08	6	5.08	30.48	15.3	3.32	3.23	3.02
651-1733622	E	SMKDS 1.5/7-5.08	7	5.08	35.56	15.3	3.86	3.75	3.51
651-1733635	E	SMKDS 1.5/8-5.08	8	5.08	40.64	15.3	4.43	4.31	4.03
651-1733651	E	SMKDS 1.5/10-5.08	10	5.08	50.8	15.3	5.48	5.33	4.99
300V @ 15A, 28-12AWG, Green Color									
651-1780015	F	KDS 3-MT	1	5.08	5.08	24.8	4.81	4.68	4.38
150V @ 15A and 300V @ 10A, 30-12AWG, Green Color									
651-1714955	G	MKDS 5/2-6.35	2	6.35	12.69	21.5	1.44	1.40	1.31

MOUSER STOCK NO. Mfr./Mfr. Part No.	Fig.	Phoenix Type	Pos.	Dimensions: mm			Price Each		
				A	B	C	1	10	50
150V @ 15A and 300V @ 10A, 30-12AWG, Green Color (Cont.)									
651-1714968	G	MKDS 5/3-6.35	3	6.35	19.04	21.5	1.98	1.92	1.80
300V @ 30A, 30-10AWG, Green Color									
651-1720033	H	SMKDS 5/2-6.35	2	6.35	12.69	21.5	1.50	1.46	1.37
651-1720046	H	SMKDS 5/3-6.35	3	6.35	19.05	21.5	2.23	2.17	2.03
300V @ 30A, 22-10AWG, Green Color									
651-1703050	I	FRONT 4-H-6.35	1	6.35	26	---	3.61	3.52	3.29
651-1703063	J	FRONT 4-V-6.35	1	6.35	26	---	3.58	3.48	3.26
651-1703076	-	D-FRONT 4-6.35	Required End Cover				.53	.513	.48
300V @ 10A, 30-14AWG, Green Color									
651-1717020	A	GMKDS 1.5/2	2	7.5	15	13.8	2.41	2.30	2.21
651-1717033	A	GMKDS 1.5/3	3	7.5	22.5	13.8	3.62	3.46	3.32
300V @ 10A, 30-14AWG, Green Color									
651-1718029	K	GSMKDSP 1.5/2	2	7.5	15	15.3	2.57	2.45	2.35
651-1718032	K	GSMKDSP 1.5/3	3	7.5	22.5	15.3	3.83	3.66	3.50
300V @ 30A, 30-10AWG, Green Color									
651-1780507	L	KDS 4	1	7.5	18	---	3.33	3.24	3.03
300V @ 10A, 30-14AWG, Green Color									
651-1717729	A	GMKDS 1.5/2-7.62	2	7.62	15.24	13.8	2.41	2.30	2.21
651-1717732	A	GMKDS 1.5/3-7.62	3	7.62	22.86	13.8	3.62	3.46	3.32
300V @ 10A, 30-14AWG, Green Color									
651-1718728	K	GSMKDSP 1.5/2-7.62	2	7.62	15.24	15.3	1.60	1.53	1.47
651-1718731	K	GSMKDSP 1.5/3-7.62	3	7.62	22.86	15.3	2.40	2.29	2.20
300V @ 30A, 24-10AWG, Green Color									
651-1703034	M	FRONT 4-H-7.62	1	7.62	28.4	---	3.70	3.60	3.37
651-1703021	N	FRONT 4-V-7.62	1	7.62	26	---	3.67	3.57	3.34
300V @ 30A and 600V @ 5A, 30-12AWG, Green Color									
651-1714971	O	MKDS 5/2-9.5	2	9.52	19.04	21.5	1.44	1.40	1.31
651-1714984	O	MKDS 5/3-9.5	3	9.52	28.56	21.5	2.12	2.06	1.93
600V @ 30A, 30-10AWG, Green Color									
651-1907432	O	MKDS 5 HV/2-9.52-Z	2	9.52	19.04	21.5	1.44	1.40	1.31
651-1907429	O	MKDS 5 HV/3-9.52-Z	3	9.52	28.56	21.5	2.71	2.64	2.47
300V @ 57A, 20-6AWG, Green Color									
651-1773976	P	MKDSP 10N/2-10.16	2	10.16	20.32	29.3	8.40	8.17	7.64
651-1929517	Q	MKDSP 10HV/2-10.16	2	10.16	20.32	30.8	9.38	9.12	8.53
651-1929520	Q	MKDSP 10HV/3-10.16	3	10.16	30.48	30.8	14.10	13.71	12.82
600V @ 125A, 20-2AWG, Green Color									
651-1932588	Q	MKDSP 25/2-15.00	2	15	30	39	9.87	9.60	8.32
651-1932591	Q	MKDSP 25/3-15.00	3	15	45	39	14.80	14.40	12.48
651-1932601	Q	MKDSP 25/4-15.00	4	15	60	39	19.75	19.21	16.65
1kV @ 192 A 2/0-16 AWG, Green Color									
651-1856126	Q	MKDSP 50/2-17.5	2	17.5	32	55	15.10	14.69	12.73
651-1856139	Q	MKDSP 50/3-17.5	3	17.5	32	55	22.67	22.05	19.11
651-1856142	Q	MKDSP 50/4-17.5	4	17.5	32	55	30.21	29.39	25.47
651-1856155	Q	MKDSP 50/5-17.5	5	17.5	32	55	33.85	31.75	29.20
651-1856168	R	MKDSP 50/1-17.5-FL	1	17.5	32	55	7.29	6.84	6.29
651-1856171	R	MKDSP 50/2-17.5-F	2	17.5	49.2	55	13.53	12.69	11.67
651-1856184	R	MKDSP 50/3-17.5-F	3	17.5	66.7	55	20.31	19.05	17.52
651-1856197	R	MKDSP 50/4-17.5-F	4	17.5	84.2	55	27.07	25.39	23.35
651-1856207	R	MKDSP 50/5-17.5-F	5	17.5	84.2	55	33.85	31.75	29.20
1kV @ 232 A 3/0-6 AWG, Green Color									
651-1841856	R	MKDSP 95/1-20 0-F	1	20	44	73	22.10	19.77	19.06
651-1841869	R	MKDSP 95/2-20 0-F	2	20	44	73	44.22	39.54	38.14
651-1841872	R	MKDSP 95/3-20 0-F	3	20	44	73	66.38	59.36	57.25
651-1841885	R	MKDSP 95/4-20 0-F	4	20	44	73	88.45	79.09	76.28
651-1841898	R	MKDSP 95/5-20 0-F	5	20	44	73	110.57	98.87	95.35