


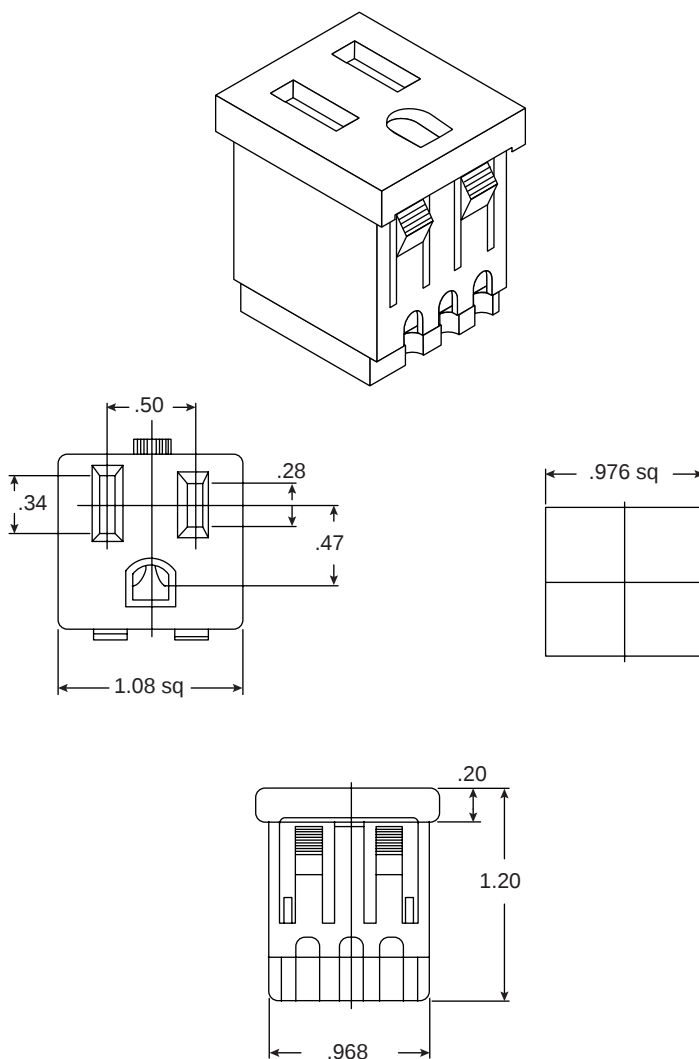

Dimensions (In.)

Specifications:

- Rating: 15A @ 125VAC
- Insulation resistance: 100MΩ (min) @ 500VDC
- Dielectric strength: 1500VAC for 1 minute
- Termination: .250" female faston (.250" mating faston terminal required for termination)
- Color: black