


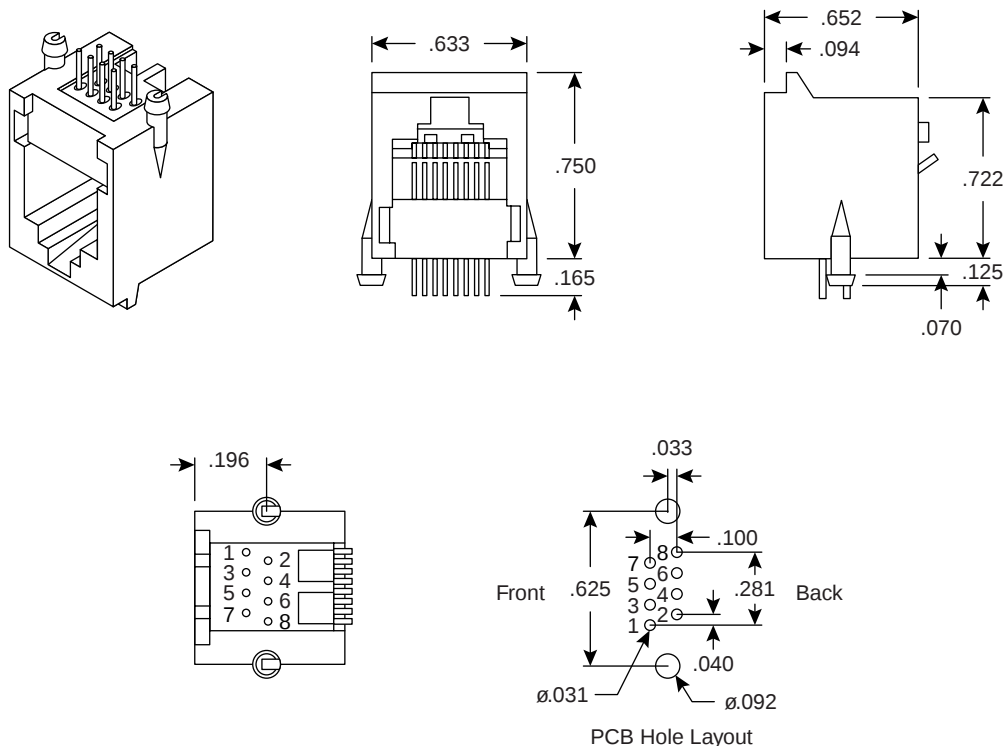

Dimensions (In.)

Specifications:

- Type: 8P8C modular phone w/PCB leads
- Housing: PBT added 15% glass fiber, 94V-0
- Color: gray
- Western Electric type: 641PCB
- USOC type: RJ45
- Contact: 6 μ gold plated phosphor bronze alloy
- Insulation resistance: 500M Ω min.
- Contact resistance: 10m Ω max. per contact
- Dielectric withstanding voltage: 1000V RMS 60Hz
- Current rating: 1.5A
- Insertion force: 900g
- Retention strength: 5kgs between jack and plug