


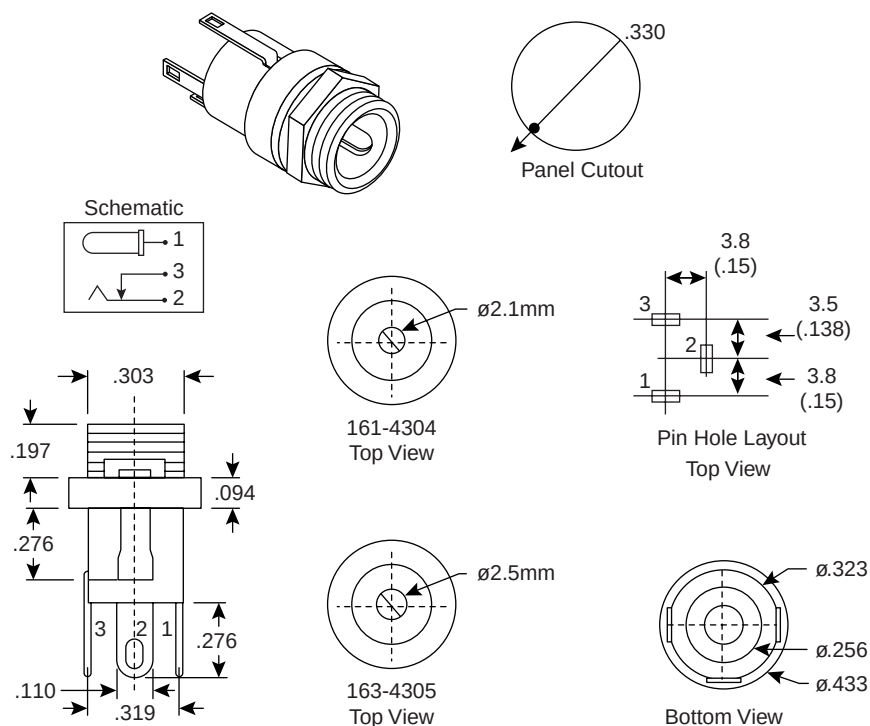

Dimensions (In.) and (mm)

Specifications:

- Type: DC power, split pin w/NC switch, chassis/panel mount
- Life: 10,000 insertion/withdrawal cycles min.
- Insertion force: 3lb. max.
- Withdrawal force: 4oz. min.
- Mating plug O.D.: 5.5mm
- Thread size: ø8 x .75mm
- Contact resistance: .010Ω max.
- Insulation resistance: 10GΩ min.
- Dielectric withstand voltage: 500VAC max.
- Contact rating: 12VDC 3A
- Washer: nickel plated steel; .315" I.D., .394" O.D.
- Nut: nickel plated brass; .065" thick, .374" across the flats
- Bushing: nickel plated brass
- Center pin, spring, contacts: silver plated brass
- Body: UL 94V-0 rated thermoplastic
- Body color: black
- Insulators: vulcanized fiber sheet
- Isolated