


Shielded Face

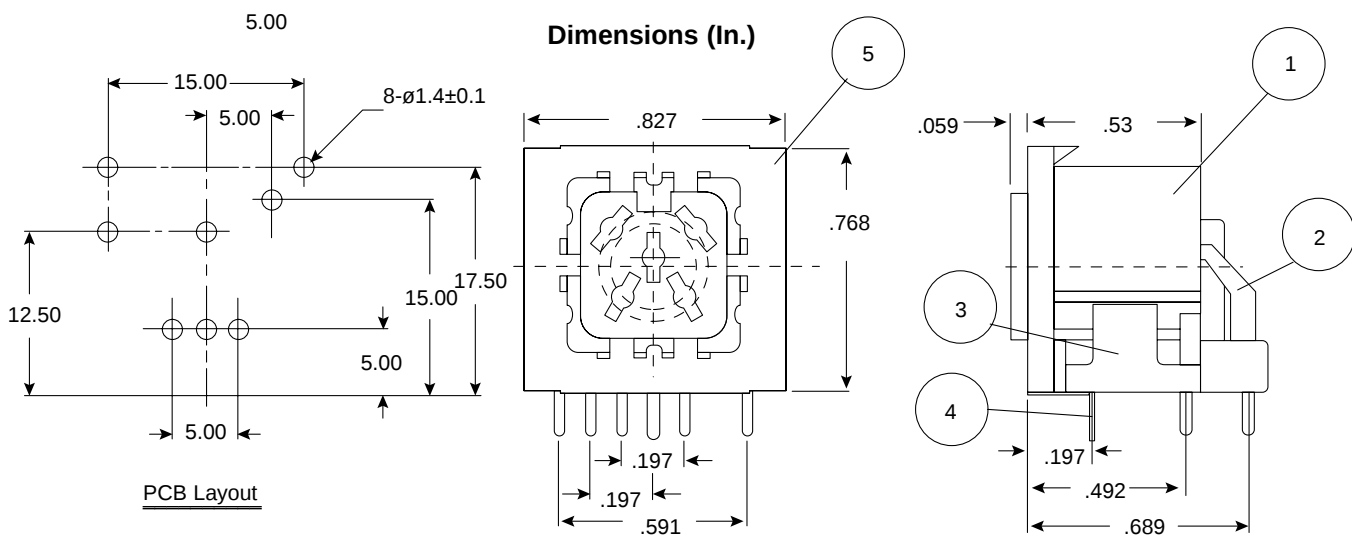

### Specifications:

- Rating: 100VAC @ 2A; 24VDC @ 1A
- Insulation resistance: 100M $\Omega$  minimum @ 500VDC
- Contact resistance: 30m $\Omega$  maximum
- Voltage rating: 500VAC for 1 minute
- Insertion force: 5KG max
- Withdrawal force: 1Kg max
- Life test: 5,000 cycles minimum

1. Body: PBT UL94V-O
2. Contact terminal: tin plated brass
3. Cover: PBT UL94V-O
4. Earth terminal: tin plated brass
5. Shielding plate: nickel plated brass

| Mouser Stock No. | Description           |
|------------------|-----------------------|
| 161-0215         | 5 pin square PC mount |