


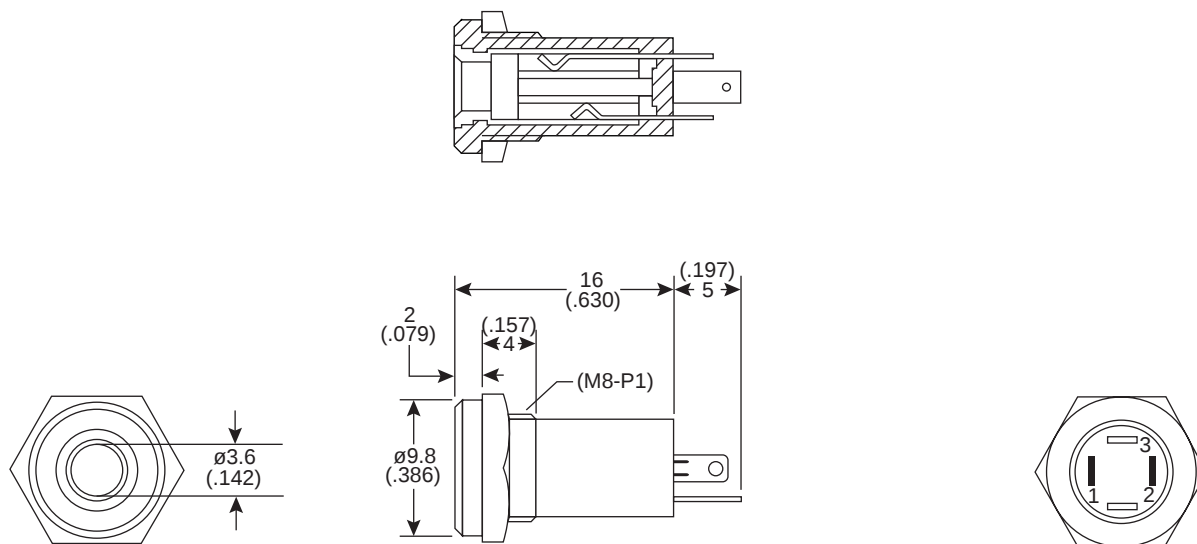

Dimensions in mm and (In.)

Specifications:

- Dielectric strength: 500V AC for one minute
- Contact resistance: 50mΩ max
- Insulation resistance: 100mΩ min. at 500V DC

Mating plugs:

17PP004, 171-3300
171-3301, 171-3308