


Dimensions (In.)

Specifications:


- Type: transmitter: 255-400ST12; receiver: 255-400SR12
- Center frequency (f_0): 40.0KHz $\pm$ 1.0KHz
- SPL@ f_0 : 255-400ST12 = 115dB (0dB re 0.0002 μ bar)
- Sensitivity @ f_0 : 255-400SR12 = -67dB (0dB = 1V/ μ bar)

- Driving voltage: 1V min., 20V max.
- Bandwidth (-6dB): 2KHz
- Allowable input power: .2W
- Capacitance @ 1KHz: 2,400pF $\pm$ 20%
- Operating temperature: -30°C ~ +85°C
- Storage temperature: -40°C ~ +100°C

Directivity (255-400ST12)

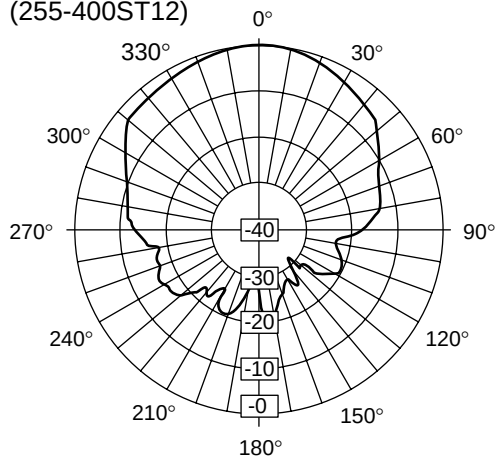

Sensitivity (255-400SR12)

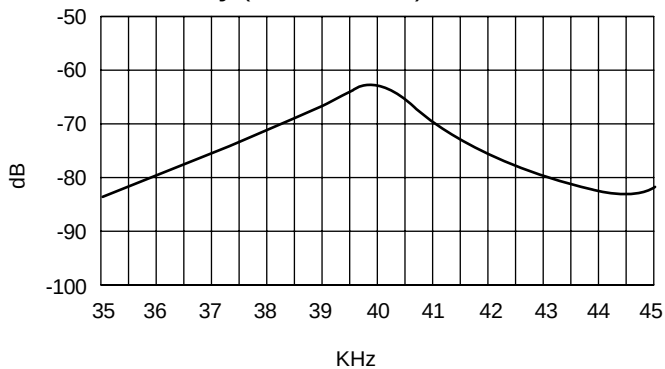

Sound Pressure (255-400ST12)

