


Dimensions (In.)

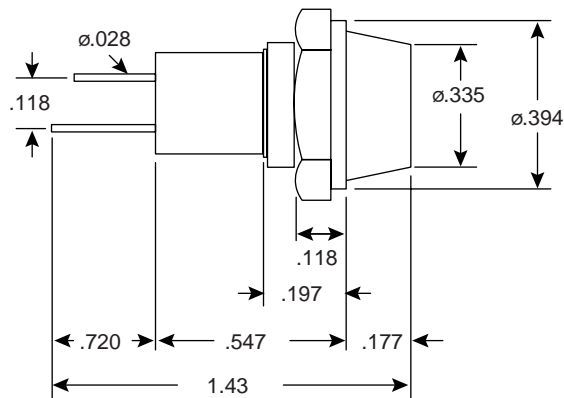

Specifications:

- Type: T-1 3/4
- Operating voltage: 2V
- Maximum current: 20mA
- Operating temperature: -25°~ +85°C
- Mounting hole: ø.335"
- Holder: chrome plated

Mouser Stock No.	Chip		Lens Color	Peak Wave-length	Electrical-Optical Characteristic		Viewing Angle °
	Material	Emitted Color			Typ.	Min.	
35CA004	GaP	Bright red	Red transparent	697	2.0	1.5	16
35CA005	GaP	Green	Green transparent	555	2.0	9.0	16
35CA006	GaP/GaAsP	Yellow	Yellow transparent	585	2.0	10.0	16
35CA007	GaP	Bright red	Red diffused	697	2.0	0.4	54
35CA008	GaP	Green	Green diffused	555	2.0	0.7	54
35CA009	GaP/GaAsP	Yellow	Yellow diffused	585	2.0	0.7	54