


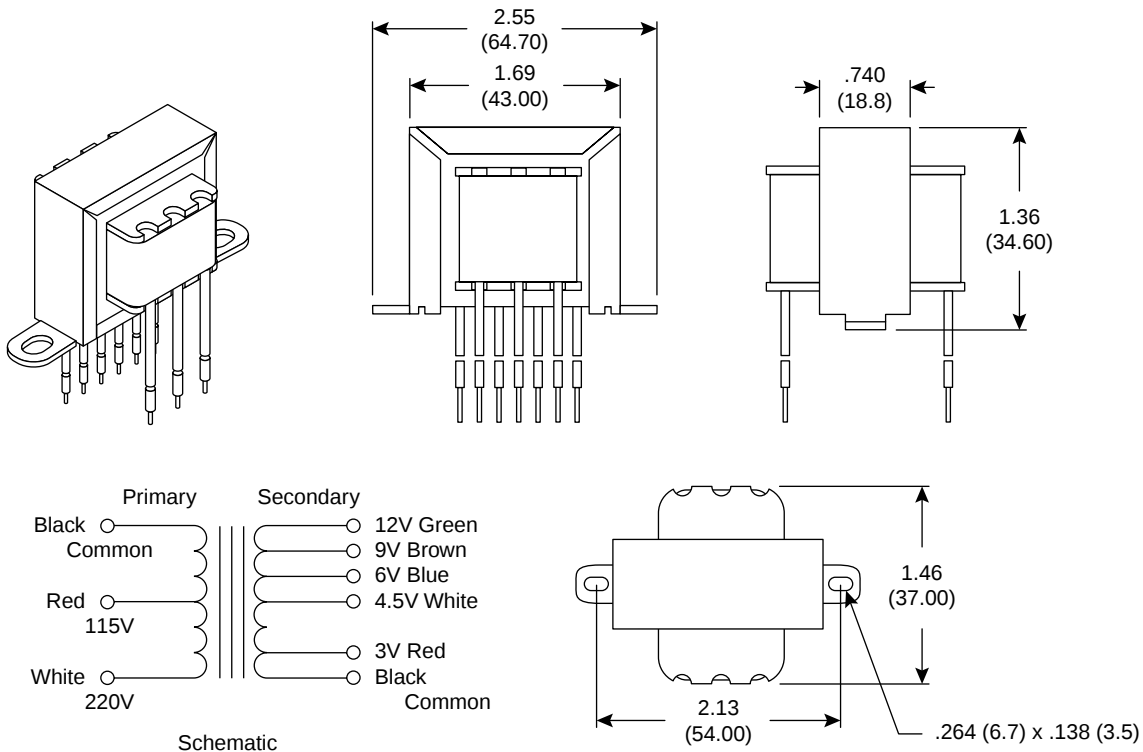

Dimensions In. (mm)

Specifications:

- Primary voltage: 115VAC(Black/Red)/220VAC(White/Red) 50/60Hz
- Primary exciting current: 40mA max.
- Secondary voltage @ 115VAC:

No load	300mA load
3.15VAC±3%	2.8VAC±3%
5.00VAC	4.3VAC
6.70VAC	5.7VAC
10.80VAC	8.7VAC
15.13VAC	11.7VAC
- Rated secondary current: .3A
- Voltage regulator: less than 15%
- Temperature rise @25°C: < 50°C
- Breakdown voltage (HiPot): 1500VAC 50Hz for 1 minute
- Coil to coil insulation: 200MΩ min. @ 500VDC
- Core size: EI-41
- Crossover insulation: 0.002" polyester tape
- Inner insulation: 3 layers of 0.002" polyester tape
- Outer wrap insulation: 3 layers of 0.002" polyester tape w/ 1 piece of fibre board
- Impregnation: varnish
- Lead wire: UL-1015 AWG22