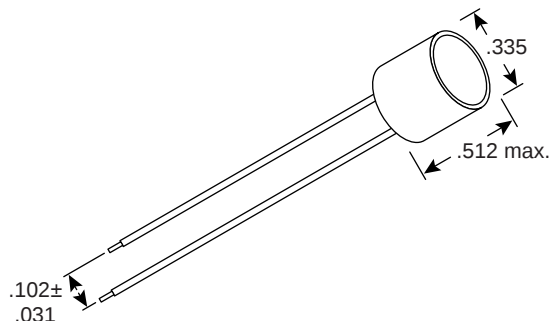



Dimensions (In.)

Miniature fixed inductor wound on a ferrite core and resin encapsulated into a molded plastic case. They exhibit excellent moisture resistance, and vibration endurance.

Specifications:

- Temperature: -25°C to +85°C
- Encapsulated
- Ferrite

Mouser Stock No.	Inductance		Tolerance	Q min.	Res. Freq. (MHz)	Test Freq. (KHz)	Current DC MA Max.	D.C. Res. Max.
	IN uH	IN mH						
434-1120-220L	22	.022	15%	30	11.0	2520	600	0.3
434-1120-330L	33	.033	15%	30	9.7	2520	500	0.35
434-1120-680L	68	.068	15%	30	7.1	2520	378	0.6
434-1120-101L	100	.100	15%	50	5.9	796	300	1.0
434-1120-151L	150	.150	15%	50	5.0	796	300	1.3
434-1120-221L	220	.220	15%	50	4.1	796	200	2.0
434-1120-331L	330	.330	15%	50	3.3	796	150	2.8
434-1120-561L	560	.560	15%	50	2.6	796	150	4.0
434-1120-103K	1000	1.000	10%	80	1.8	252	100	5.5
434-1120-123K	1200	1.200	10%	80	1.6	252	100	6.0
434-1120-153K	1500	1.500	10%	80	1.45	252	100	7.0
434-1120-223K	2200	2.200	10%	80	1.1	252	100	9.0
434-1120-393K	3900	3.900	10%	80	0.74	252	87	15.0
434-1120-473K	4700	4.700	10%	80	0.63	252	80	20.0
434-1120-104K	10000	10.000	10%	80	0.21	79.6	58	40.0
434-1120-124K	12000	12.000	10%	80	0.11	79.6	50	45.0