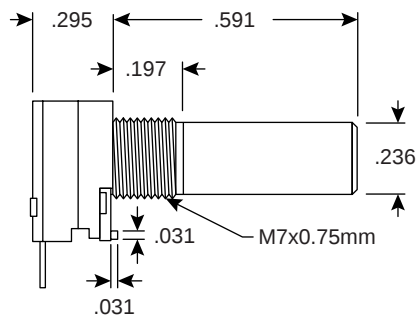
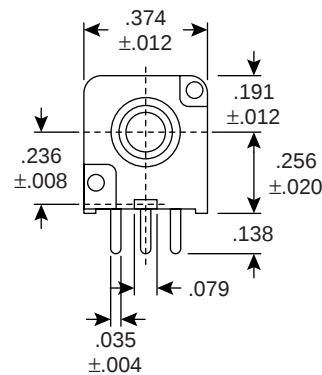
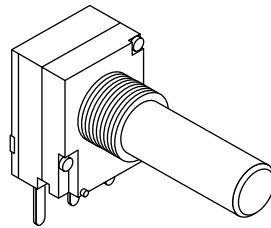


Dimensions (In.)
(except where noted)

Specifications:

- Taper: linear
- Rated wattage: 0.05W
- Insulation resistance: >100MΩ @ 250VDC
- Breakdown voltage: 300VAC for 1 minute
- Rotation angle: 300°±5°
- Rotation torque: 20~250g/cm
- Values: 1K, 5K, 10K, 50K, 100K