




## FCI 4-Way APEX 2.8 mm Connection System

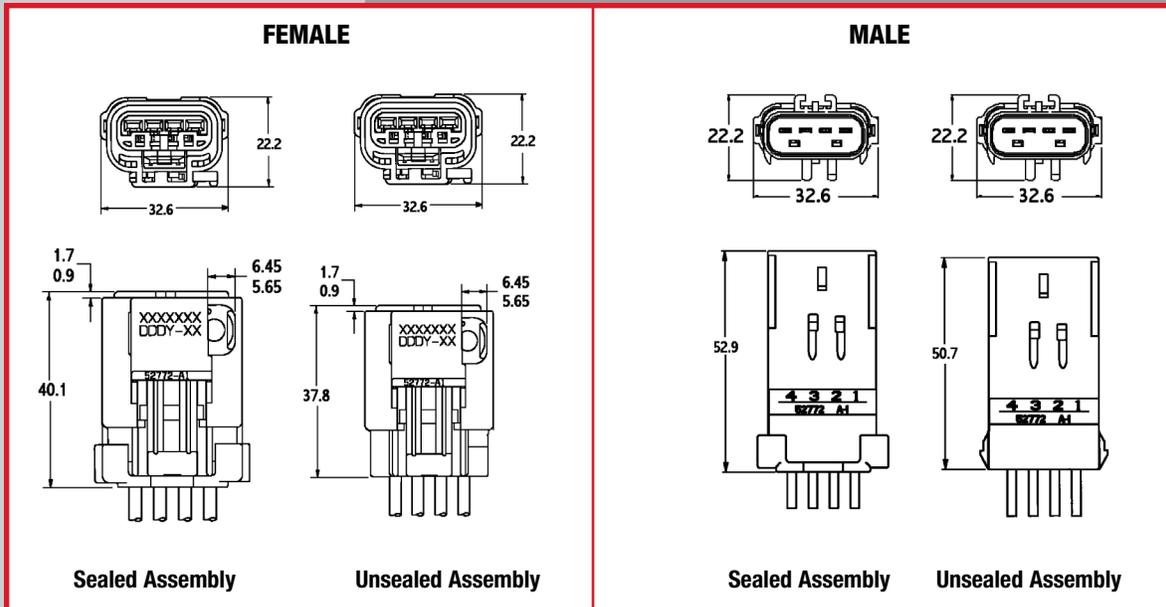

INDEX TYPE	HOUSING COLOR	SEALED/ UNSEALED	FEMALE ASSEMBLY PART NUMBER	MALE ASSEMBLY PART NUMBER	TEMPERATURE RATING OF MATERIAL	WIRE INSULATION RANGE PER CAVITY (mm)
A	BLK	SEALED	54200409	54200413	-40°C to +125°C	1.70 – 2.77
A	BLK	UNSEALED	54200400	54200405	-40°C to +125°C	1.50 – 4.09
B	LT GREY	SEALED	54200410	54200414	-40°C to +125°C	1.70 – 2.77
C	DK GREY	SEALED	54200411	54200415	-40°C to +125°C	1.70 – 2.77
C	DK GREY	UNSEALED	54200403	54200407	-40°C to +125°C	1.50 – 4.09
D	NATURAL	SEALED	54200412	54200416	-40°C to +125°C	1.70 – 2.77
D	NATURAL	UNSEALED	54200404	54200408	-40°C to +125°C	1.50 – 4.09
B	LT GREY	SEALED	54000450*	—	SEAL W/O HOLES	USED AS CAP
A	BLACK	SEALED	—	54200427*	SEAL W/O HOLES	USED AS CAP

\* Plug for same index (A) mating part.

Note: Female part numbers with the N suffix are without CPA latch.

3.35mm wire diameter sealing is available in select configurations. Consult sales drawing.

Additional configurations available. Please consult sales drawing.