
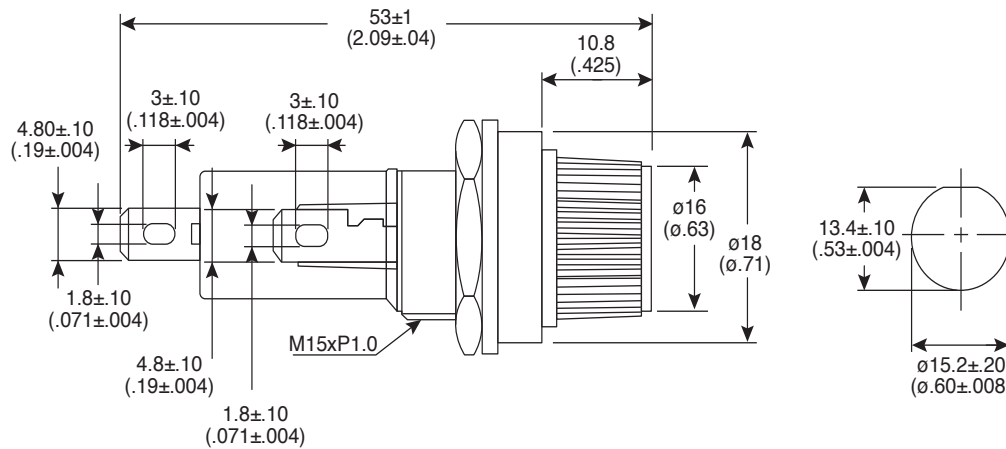


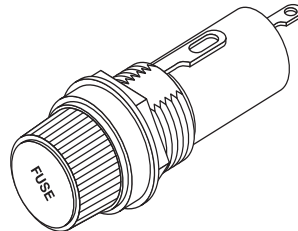

Dimensions: mm (in.)

SPECIFICATIONS

Rating:	10A/250VAC
Insulation Resistance:	500VDC 100MΩ Min.
Dielectric Strength:	1500VAC for 1 minute
Fuse Size:	ø6.0x30mm ø6.35x31.8mm
Type:	Standard panel mount for 1/4" fuses
Cap Color:	Black
RoHS Compliant by Exemption	

Available from Mouser Electronics
1-800-346-6873 / www.mouser.com

EPD-200564