


4 Position Dimmer for LED Light Panels from Inspired LED

Specifications:	
Supply Voltage: DC 12VDC	Size: (L) 58 x (W) 36 x (H) 10 mm
Max load current: 2 Amp	Net Weight: 15g
Output: 1 channel	Working Temperature -20- 60°C
Static power consumption: < 1 Watt	
Output Power: 24 Watts	
Function 4 Position Dimmer 0, 10, 20, 50 & 100% using PWM	

Unit Diagram

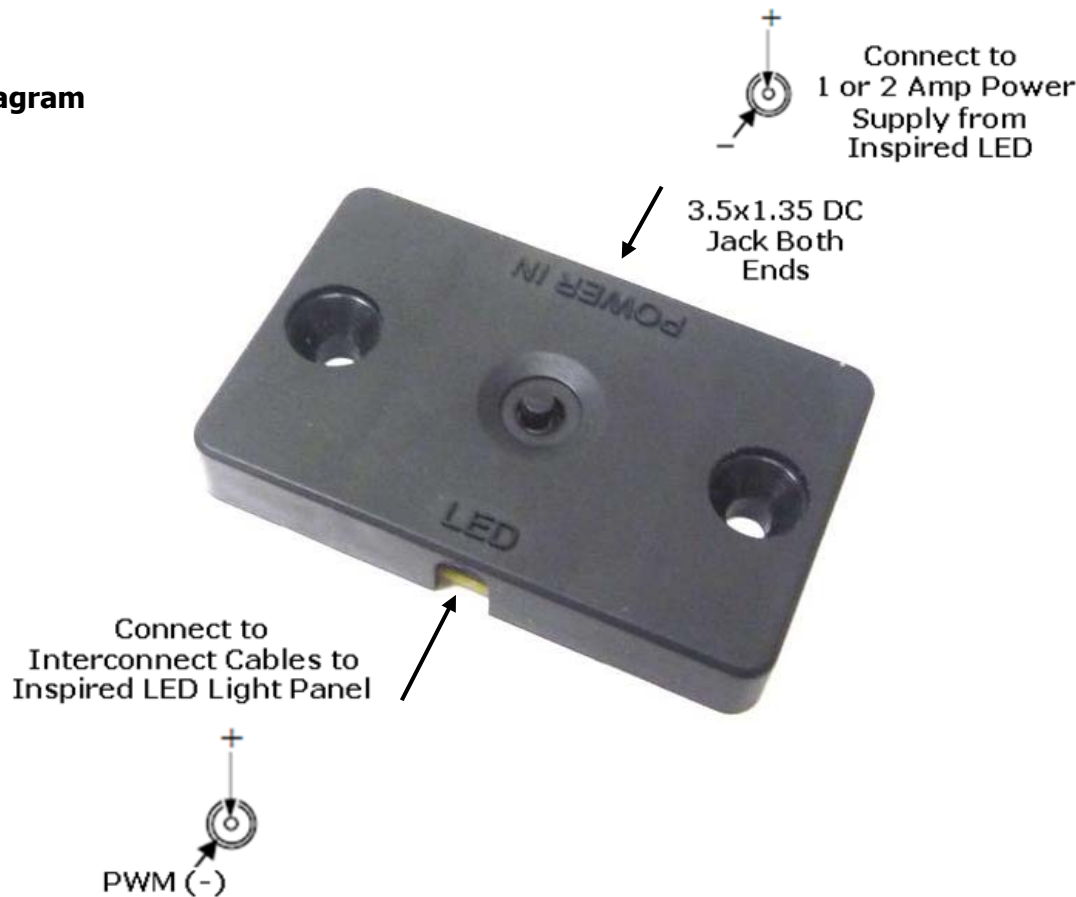

Safety Information:

1. Supply Voltage of this product is 12 VDC, Do not exceed.
2. Sorting Output wires may cause damage to dimmer.
3. Always observe proper polarity when connecting power and load.
4. For indoor use only – This product is not waterproof or weatherproof.

Note: If the Dimmer does not function check that the power is plugged into the POWER IN connector.