


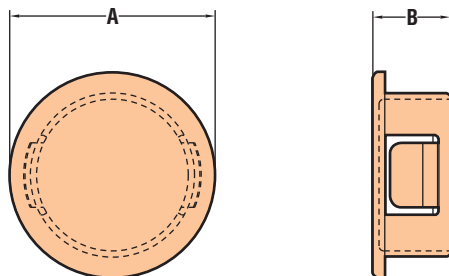

Heyco® Pry Out Plugs

MOUNTING HOLE DIAMETER		PART NO.		DESCRIPTION	PART DIMENSIONS			
in.	mm.	Black	White		Head in.	Diameter mm.	Overall in.	Height mm.
Clearance Fit for Panel Thickness up to .156~ (4,0 mm)								
.250	6,4	3053	3054	POP 250	.421	10,7	.328	8,3
Clearance Fit for Panel Thickness up to .172~ (4,4 mm)								
.312	7,9	3056	3057	POP 312	.510	12,9	.406	10,3
.375	9,5	3059	3060	POP 375	.578	14,7		
.437	11,1	3062	3063	POP 437	.609	15,5		
.500	12,7	3065	3066	POP 500	.671	17,0		
.562	14,3	3068	3069	POP 562	.734	18,6		
.625	15,9	3071	3072	POP 625	.796	20,2		
.687	17,4	3074	3075	POP 687	.890	22,6		
.750	19,0	3077	3078	POP 750	.968	24,6		
.812	20,6	3080	3081	POP 812	1.031	26,2		
.875	22,2	3083	3084	POP 875	1.078	27,4		
1.000	25,4	3086	3087	POP 1000	1.218	30,9		
1.093	27,8	3089	3090	POP 1093	1.296	32,9		
1.187	30,1	3092	3093	POP 1187	1.406	35,7	.453	11,5
1.250	31,8	3095	3096	POP 1250	1.453	36,9		
1.375	34,9	3098	3099	POP 1375	1.578	40,1		
Clearance Fit for Panel Thickness up to .250~ (6,4 mm)								
1.500	38,1	3124	3125	POP 1500	1.718	43,6	.453	11,5
1.750	44,5	2973	2974	POP 1750	1.980	50,3	.475	12,1
2.000	50,8	2798	2799	POP 2000	2.218	56,4	.483	12,3
2.500	63,5	2975	2976	POP 2.5	2.691	68,4	.741	18,8

Standard color black. Consult Heyco for other colors.



Material

Nylon 6/6

Certifications



Recognized under the Component Program of Underwriters' Laboratories, File E51579



Certified by the Canadian Standards Association, File 8919

Flammability Rating

94V-2

Material Temperature Index

257°F (125°C)—Maximum temperature on part not to exceed 221°F (105°C)

*Quick
Specs*