

Part Number: MV4020-13HL





Features

Coreless Motor
 Printed Circuit Mount

Electrical Specifications

Rated Voltage	1.3 V DC
Rated Current	90 mA
Rated Speed	9000 +/- 2000 RPM
Starting Voltage	0.9 V Max.
Stall Current	120 mA Max.

Custom Connectors Available

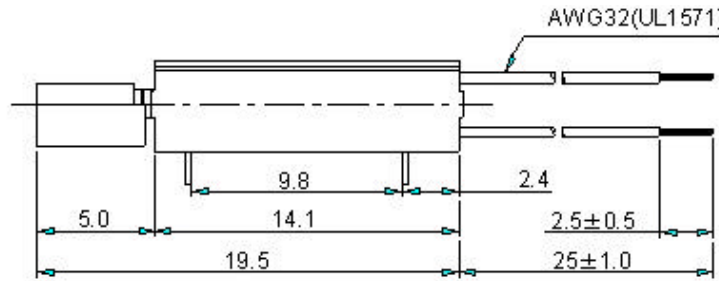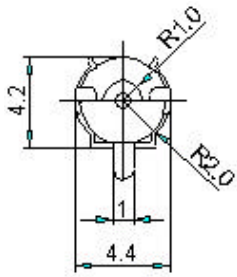

NOTES:

1. ALL DIMENSIONS ARE IN MILLIMETERS.
2. SPECIFICATION SUBJECT TO CHANGE
OR WITHDRAWAL WITHOUT NOTICE.

For application notes and detail drawing specifications, please consult www.projectsunlimited.com.

Specifications subject to change without notice.

© 2000, Projects Unlimited Inc., All Rights Reserved.