


561-13SP005, 561-13SP037, 561-13SP047,
561-13SP061, 561-13SP096, 561-13SP097,
561-13SP213, 561-13SP218, 561-13SP223

Last Revised: 1/28/10

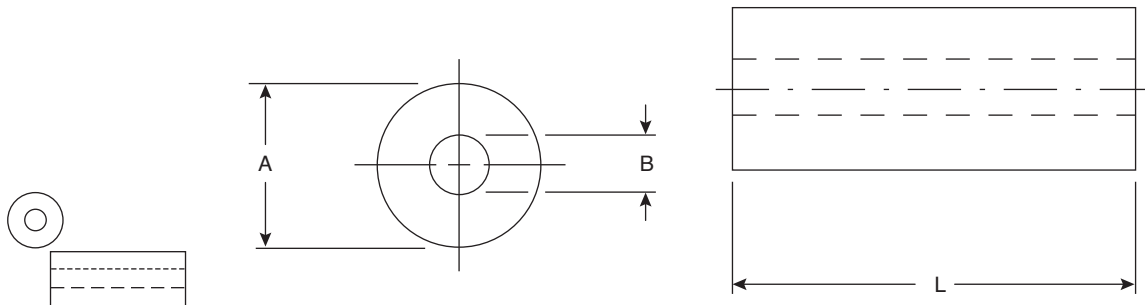

Dimensions: in.

All standard nylon Spacers can be tapped two thread sizes larger than the screw listed. For example: 13SP005 with a screw size of 2 can be tapped 440 thread.

• Molded in Natural Nylon 6/6 • RoHS Compliant

Item Number	Description	A	B	L	Screw
561-13SP005	SP 5	0.187	0.091	0.250	2.000
561-13SP037	SP 37	0.250	0.140	0.187	6.000
561-13SP047	SP 47	0.250	0.091	0.375	2.000
561-13SP061	SP 61	0.250	0.140	0.562	6.000
561-13SP096	SP 96	0.312	0.140	0.187	6.000
561-13SP097	SP 97	0.312	0.171	0.187	8.000
561-13SP213	SP 213	0.500	0.140	0.250	6.000
561-13SP218	SP 218	0.500	0.140	0.312	6.000
561-13SP223	SP 223	0.500	0.140	0.375	6.000