


Split Loom Tubing

561-SL250PE, 561-SL375PE, 561-SL500PE, 561-SL625PE, 561-SL750PE, 561-SL1000PE, 561-SL250PP, 561-SL375PP, 561-SL500PP, 561-SL625PP, 561-SL750PP, 561-SL1000PP, 561-SL250FRPP, 561-SL375FRPP, 561-SL500FRPP, 561-SL625FRPP, 561-SL750FRPP, 561-SL1000FRPP, 561-SL250NYGY, 561-SL375NYGY, 561-SL500NYGY, 561-SL625NYGY, 561-SL750NYGY, 561-SL1000NYGY

DIMENSIONS: in.

Date Last Revised: 11-13-12

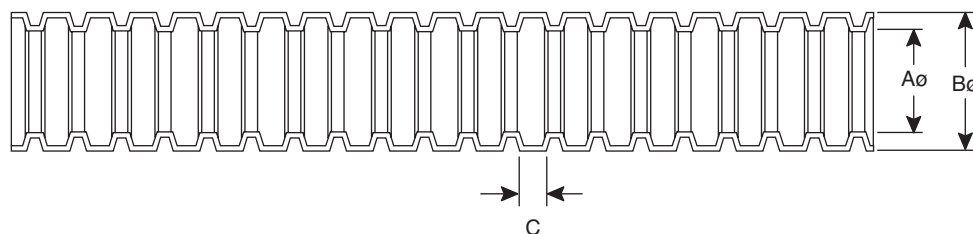

MOUSER STOCK NO.	Description	A	B	C	Package Type
561-SL250PE	1/4" Polyethylene	0.266 (ref.)	0.395 (ref.)	0.120 (ref.)	100" Coil
561-SL375PE	3/8" Polyethylene	0.419 (ref.)	0.535 (ref.)	0.128 (ref.)	100" Coil
561-SL500PE	1/2" Polyethylene	0.505 (ref.)	0.670 (ref.)	0.143 (ref.)	100" Coil
561-SL625PE	5/8" Polyethylene	0.650 (ref.)	0.825 (ref.)	0.145 (ref.)	100" Coil
561-SL750PE	3/4" Polyethylene	0.761 (ref.)	0.927 (ref.)	0.144 (ref.)	100" Coil
561-SL1000PE	1" Polyethylene	0.909 (ref.)	1.033 (ref.)	0.172 (ref.)	100" Coil
561-SL250PP	1/4" Polypropylene	0.266 (ref.)	0.395 (ref.)	0.120 (ref.)	100" Coil
561-SL375PP	3/8" Polypropylene	0.419 (ref.)	0.535 (ref.)	0.128 (ref.)	100" Coil
561-SL500PP	1/2" Polypropylene	0.505 (ref.)	0.670 (ref.)	0.143 (ref.)	100" Coil
561-SL625PP	5/8" Polypropylene	0.650 (ref.)	0.825 (ref.)	0.145 (ref.)	100" Coil
561-SL750PP	3/4" Polypropylene	0.761 (ref.)	0.927 (ref.)	0.144 (ref.)	100" Coil
561-SL1000PP	1" Polypropylene	0.909 (ref.)	1.033 (ref.)	0.172 (ref.)	100" Coil
561-SL250FRPP	1/4" Flame Retardent Polypropylene	0.266 (ref.)	0.395 (ref.)	0.120 (ref.)	100" Coil
561-SL375FRPP	3/8" Flame Retardent Polypropylene	0.419 (ref.)	0.535 (ref.)	0.128 (ref.)	100" Coil
561-SL500FRPP	1/2" Flame Retardent Polypropylene	0.505 (ref.)	0.670 (ref.)	0.143 (ref.)	100" Coil
561-SL625FRPP	5/8" Flame Retardent Polypropylene	0.650 (ref.)	0.825 (ref.)	0.145 (ref.)	100" Coil
561-SL750FRPP	3/4" Flame Retardent Polypropylene	0.761 (ref.)	0.927 (ref.)	0.144 (ref.)	100" Coil
561-SL1000FRPP	1" Flame Retardent Polypropylene	0.909 (ref.)	1.033 (ref.)	0.172 (ref.)	100" Coil
561-SL250NYGY	1/4" Nylon	0.266 (ref.)	0.395 (ref.)	0.120 (ref.)	100" Coil
561-SL375NYGY	3/8" Nylon	0.419 (ref.)	0.535 (ref.)	0.128 (ref.)	100" Coil
561-SL500NYGY	1/2" Nylon	0.505 (ref.)	0.670 (ref.)	0.143 (ref.)	100" Coil
561-SL625NYGY	5/8" Nylon	0.650 (ref.)	0.825 (ref.)	0.145 (ref.)	100" Coil
561-SL750NYGY	3/4" Nylon	0.761 (ref.)	0.927 (ref.)	0.144 (ref.)	100" Coil
561-SL1000NYGY	1" Nylon	0.909 (ref.)	1.033 (ref.)	0.172 (ref.)	100" Coil

SPECIFICATIONS

All split loom is manufactured in Black

All nylon split loom has a Gray stripe for identification

All FR polypropylene split loom has a blue stripe

RoHS Compliant

Available from Mouser Electronics
1-800-346-6873 / www.mouser.com

EPD-200898

Specifications are subject to change without notice. No liability or warranty implied by this information. Environmental compliance based on producer documentation.