




Colored Split Loom Tubing

561-SL250PERD, 561-SL250PEYW, 561-SL250PEGR,
561-SL375PERD, 561-SL375PEYW, 561-SL375PEGR, 561-SL500PERD, 561-SL500PEYW, 561-SL500PEGR,
561-SL625PERD, 561-SL625PEYW, 561-SL625PEGR, 561-SL750PERD, 561-SL750PEYW, 561-SL750PEGR,
561-SL1000PERD, 561-SL1000PEYW, 561-SL1000PEGR

DIMENSIONS: in.

Date Last Revised: 3-20-2014

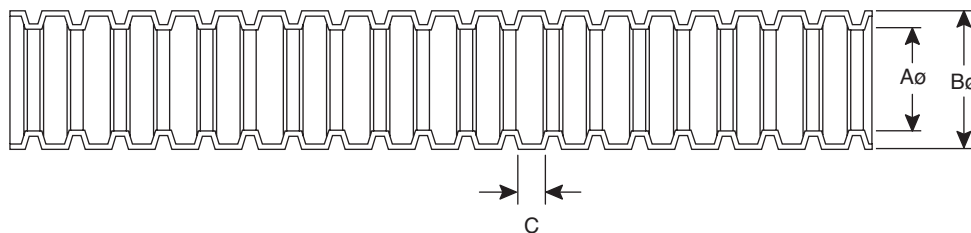

MOUSER STOCK NO.	Description	A	B	C	Package Type
561-SL250PERD	1/4" Polyethylene Red	0.266	0.395	0.120	100" Roll
561-SL250PEYW	1/4" Polyethylene Yellow	0.266	0.395	0.120	100" Roll
561-SL250PEGR	1/4" Polyethylene Green	0.266	0.395	0.120	100" Roll
561-SL375PERD	3/8" Polyethylene Red	0.419	0.535	0.128	100" Roll
561-SL375PEYW	3/8" Polyethylene Yellow	0.419	0.535	0.128	100" Roll
561-SL375PEGR	3/8" Polyethylene Green	0.419	0.535	0.128	100" Roll
561-SL500PERD	1/2" Polyethylene Red	0.505	0.670	0.143	100" Roll
561-SL500PEYW	1/2" Polyethylene Yellow	0.505	0.670	0.143	100" Roll
561-SL500PEGR	1/2" Polyethylene Green	0.505	0.670	0.143	100" Roll
561-SL625PERD	5/8" Polyethylene Red	0.650	0.825	0.145	100" Roll
561-SL625PEYW	5/8" Polyethylene Yellow	0.650	0.825	0.145	100" Roll
561-SL625PEGR	5/8" Polyethylene Green	0.650	0.825	0.145	100" Roll
561-SL750PERD	3/4" Polyethylene Red	0.761	0.927	0.144	100" Roll
561-SL750PEYW	3/4" Polyethylene Yellow	0.761	0.927	0.144	100" Roll
561-SL750PEGR	3/4" Polyethylene Green	0.761	0.927	0.144	100" Roll
561-SL1000PERD	1" Polyethylene Red	0.909	1.033	0.172	100" Roll
561-SL1000PEYW	1" Polyethylene Yellow	0.909	1.033	0.172	100" Roll
561-SL1000PEGR	1" Polyethylene Green	0.909	1.033	0.172	100' Roll

Available from Mouser Electronics
1-800-346-6873 / www.mouser.com

EPD-200922

Specifications are subject to change without notice. No liability or warranty implied by this information. Environmental compliance based on producer documentation.