


RF Wireless LED Dimmer from Inspired LED



The wireless RF LED Dimmer is an excellent option for dimming an Inspired LED lighting system. Simply plug an Inspired LED 12V power supply into the controller box, connect the lighting to the remaining terminals and the system is now under control of the included remote. Select from 50 intermediate brightness levels (1% to 100%) with the touch wheel. Turn the entire system on and off with the remote - when the system is turned back on, the previous setting will be resumed. Works with all Inspired LED lighting.

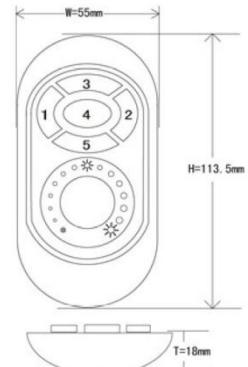

How to Use the LED Dimmer	
Connect Power	Plug 12V Inspired LED Power Supply into the connector marked "PWR IN".
Connect LEDs	Plug all lights to be dimmed into either, or both, of the two terminals marked "LED".
Dimming Control	Select desired brightness from 50 grades using the touch wheel. Or select "High", "Medium", or "Low" from keys 3, 4, and 5 respectively.
Remote Match	Press 'Key 3' once within three seconds of connecting power to the controller to match the remote to the controller. The connected lights will blink 3 times if successfully matched. One remote may be matched to multiple controllers.
Remote Clear	Press 'Key 3' five times within three seconds of connecting power to the controller to clear a remote from a controller. The connected lights will blink 6 times if successfully cleared and the remote will no longer influence the controller.
Remote Sensitivity	Please don't touch or press the touch wheel within 3 seconds of loading the batteries to protect the sensitivity of the remote. If the touch wheel loses sensitivity, remove and reinstall the batteries.

Key	Function
1	On
2	Off
3	Highest Brightness
4	Medium Brightness
5	Lowest Brightness

