
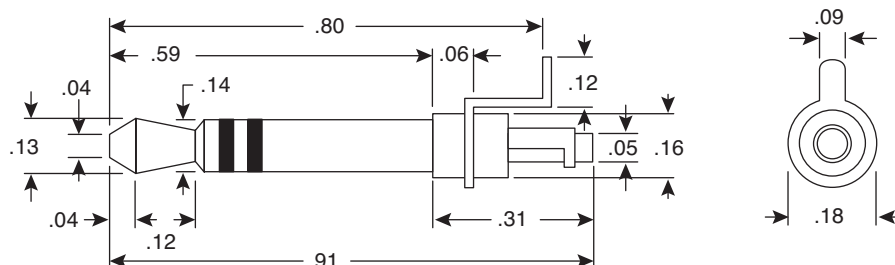


Plug

171-3204

KOBI CONN

Plug

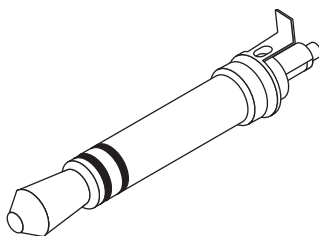

Dimensions: In.

SPECIFICATIONS	
Type:	stereo, custom molding application, straight or right angle
Temperature rating:	110°C
Insulation resistance:	100Ω min. @ 500VDC
Contact resistance:	50mΩ max.
Withstand voltage:	500VAC for 1 minute
Insulator:	duracon
Terminal:	nickel plated steel
Tip, ring, & sleeve:	nickel plated brass
Size:	3.5mm
Circuit:	stereo

Application Note:

Electrical conductivity of this plug could be effected if the molding process is not precisely controlled and engineered correctly. Factors such as temperature, pressure, and material used in the molding process can have an effect on the item being molded. Mouser has no control over these factors or the molding process and does not know enough about the various molding processes to recommend one for use. The user must determine the suitability of this product for his/her molding process.

Date Last Revised: 6/21/12

Available from Mouser Electronics
1-800-346-6873
www.mouser.com

KC-300053

Specifications are subject to change without notice. No liability or warranty implied by this information. Environmental compliance based on producer documentation.

171-3204