 

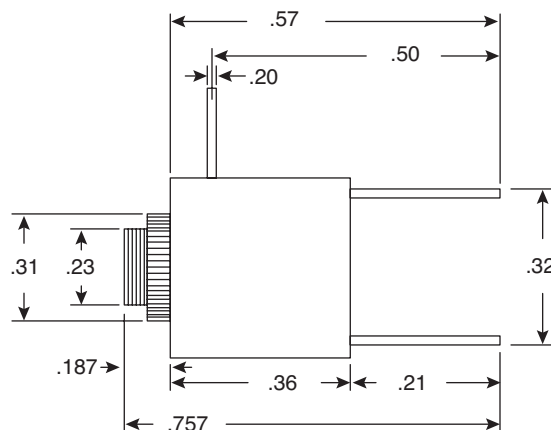
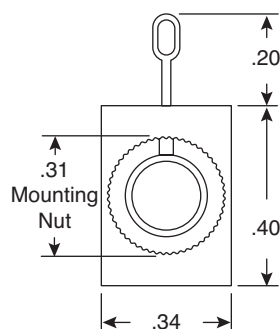


3.5mm Jack

16PJ135

KOBICONN

3.5mm Jack

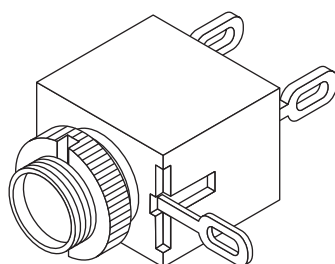

Schematic

Dimensions: In.

SPECIFICATIONS	
Type:	Mono Phone Jack
Housing:	Black ABS Plastic
Mounting Hole:	.25"
Temperature Rating:	185°C
Contacts:	Nickel Plated Brass
Switch:	N/C w/ spring
Mount:	Chassis
Mechanical Life:	5,000 cycles

Date Last Revised: 6/21/12

Available from Mouser Electronics
1-800-346-6873
www.mouser.com

KC-300084

Specifications are subject to change without notice. No liability or warranty implied by this information. Environmental compliance based on producer documentation.

16PJ135