
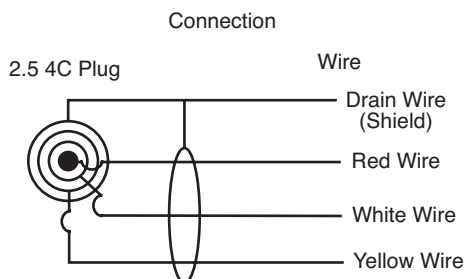


2.5mm 4 Conductor Cable

172-7425

KOBI CONN

2.5mm 4 Conductor Cable

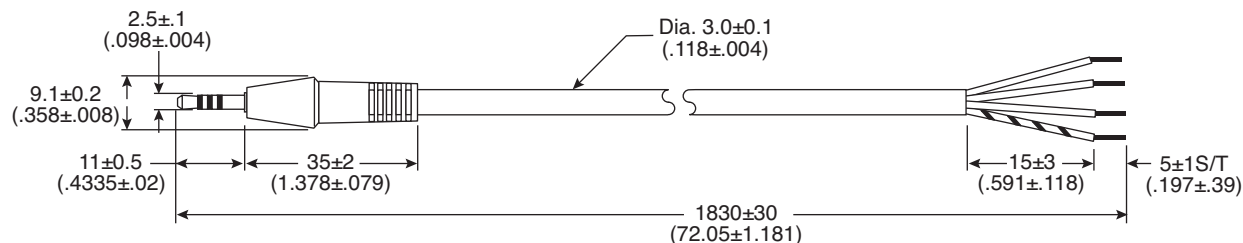

Mechanical Specifications

2.5mm 4C Plug:	Stripped to Tinned
Cable:	(7/0.127T X3C+35 \pm 2/0.127T) X IC Dia=3.0 3C Shield with Black P.V.C. Jacket
Temperature:	60°C
Colors:	Red to Tip, White to Ring, Yellow to Ring, Shield to Sleeve
Size:	Black, 6ft. Long

Electrical Specifications

Voltage Rating:	24V DC
------------------------	--------

Date Last Revised: 6/21/12

Available from Mouser Electronics
1-800-346-6873
www.mouser.com

KC-300139

Specifications are subject to change without notice. No liability or warranty implied by this information. Environmental compliance based on producer documentation.

172-7425