


3.5mm Right Angle 4 Conductor Cable


172-7436

KOBICONN

3.5mm Right Angle 4 Conductor Cable

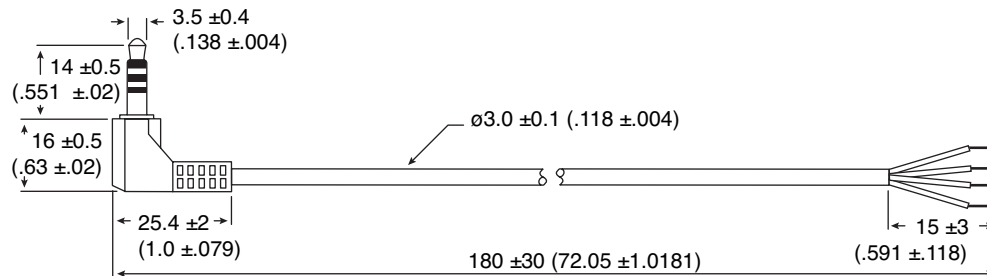

Connection

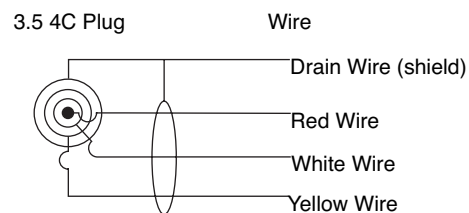

Dimensions: mm (In.)

Electrical Specifications

Voltage Rating: 24V DC.

Mechanical Specifications

Temperature:	60°C
Color:	Black
Length:	6 feet Long
Plug:	3.5mm 4C Plug Right Angle to Stripped and Tinned
Wires:	Red to tip White to ring Yellow to ring Shield to sleeve
Cable:	(7/0.127T x 3C + 35 ±2/0.127T) x 1C ø3.0 3C Shield w/ Black PVC Jacket

Date Last Revised: 6/21/12

Available from Mouser Electronics
1-800-346-6873
www.mouser.com

KC-300140

172-7436

Specifications are subject to change without notice. No liability or warranty implied by this information. Environmental compliance based on producer documentation.