


2.5mm Power Cable

172-0014

KOBI CONN

2.5mm Power Cable

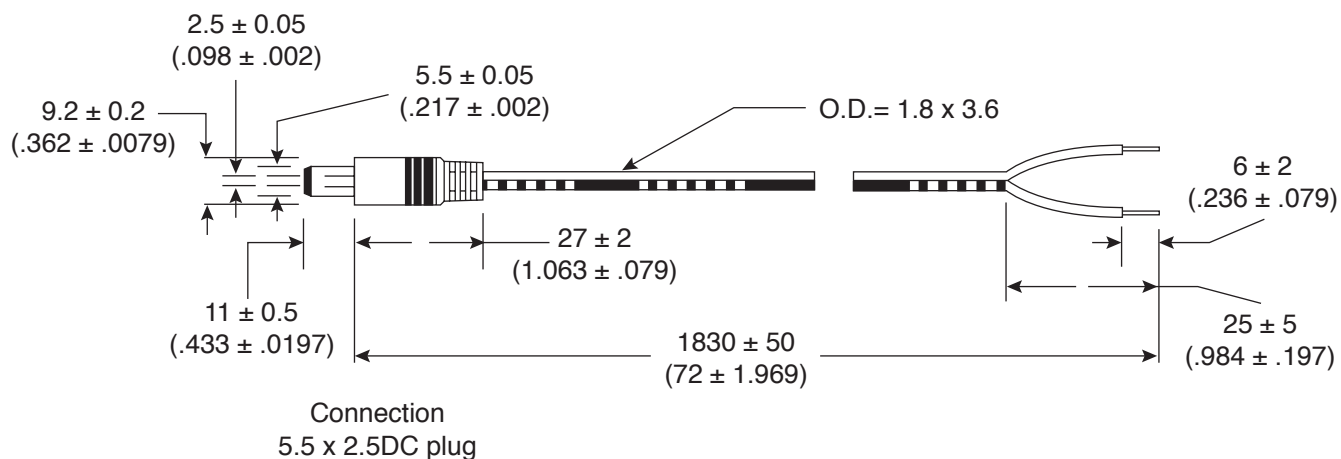

DIMENSIONS: mm (In.)

SPECIFICATIONS	
Type:	2.5 x 5.5 x11 DC plug to stripped and tinned
Wire:	24AWG gray 2F (11/0.16X2F) Length=72"
Temperature:	60° C
Voltage rating:	300V DC
Resistance:	0.15 Ω per meter

Date Last Revised: 10-19-05

Available from Mouser Electronics
1-800-346-6873
www.mouser.com

KC-300330

172-0014