


DC Power Cable

172-4207

KOBICONN

DC Power Cable

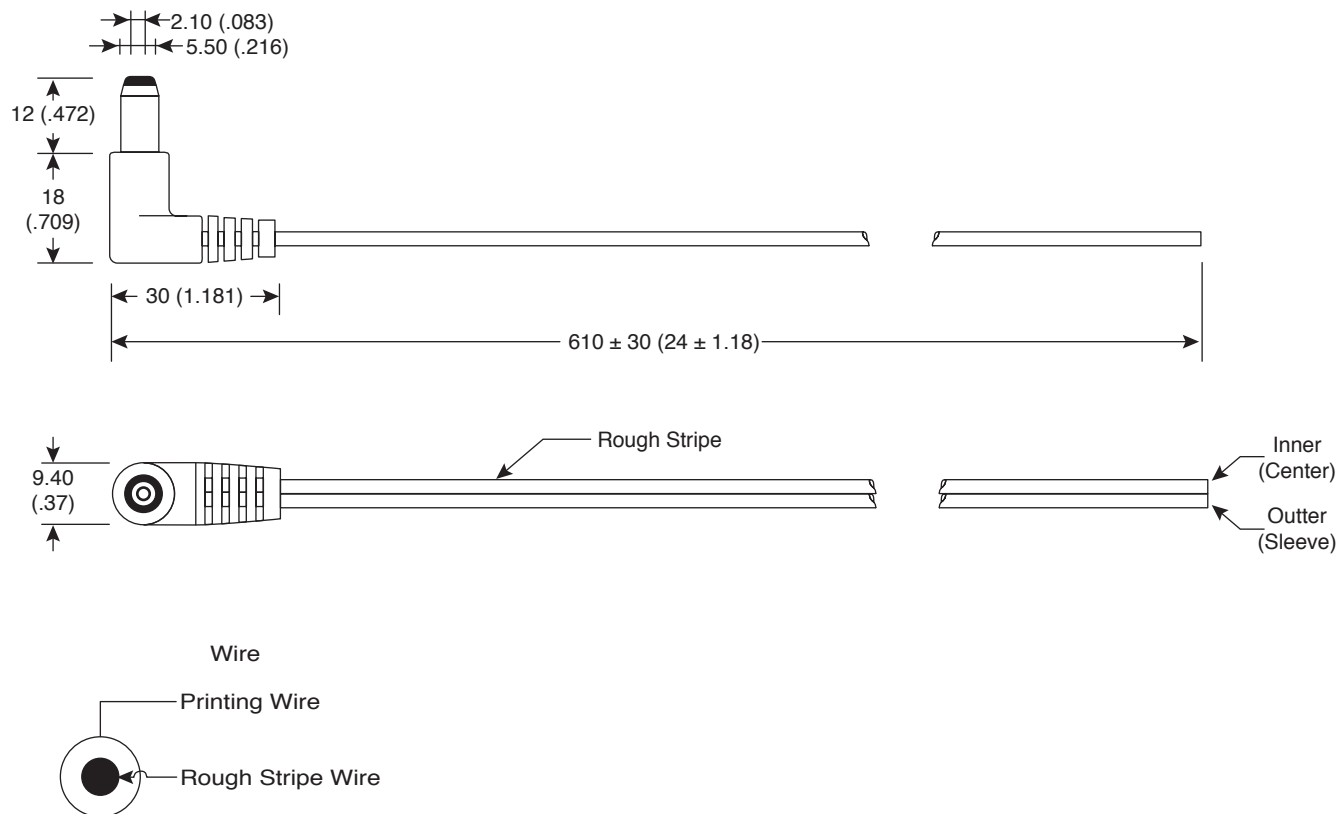

DIMENSIONS: mm (In.)

SPECIFICATIONS	
5.5:	2.1 right angle DC plug to cut
18AWG X 2 F SPT:	1 2ft. long black color
Temperature:	60°C.
Voltage rating:	300V
Center:	To rough stripe wire
Sleeve:	To printing wire

Date Last Revised: 6-27-05

Available from Mouser Electronics
1-800-346-6873
www.mouser.com

KC-300334

172-4207