


Cable

172-0008

KOBI CONN

Cable

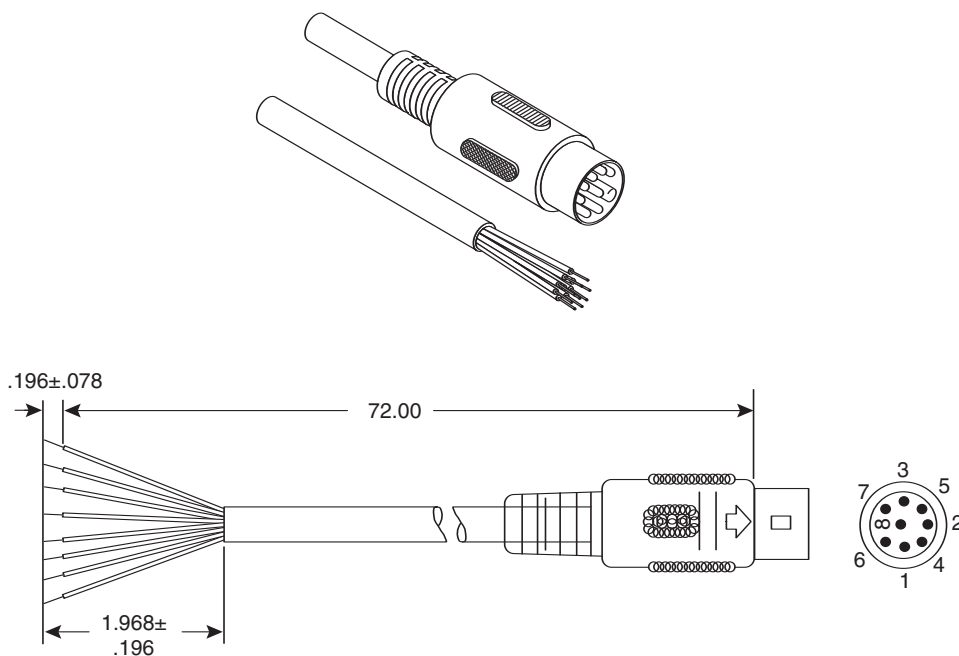

DIMENSIONS: IN

SPECIFICATIONS	
Type:	DIN plug to Stripped and Tinned
Conductor:	8C, 24AWG
Shield:	Mylar Wrapped
Cable O.D.:	5.0m/m, 6 Ft.
Color:	Black
Temperature Rating:	60°C
Voltage Rating:	300V
Plug:	8 Pin DIN, 270°
Wire Color Coding:	Red (pin 1), Yellow (pin 2), Blue (pin 3), Orange (pin 4), Green (pin 5), Brown (pin 6), Gray (pin 7), & Violet (pin 8)

Date Last Revised: 4-5-05

Available from Mouser Electronics
1-800-346-6873
www.mouser.com

KC-300361

172-0008