


4 Conductor Sub-Miniature Jack

161-6425

KOBICONN

4 Conductor Sub-Miniature Jack

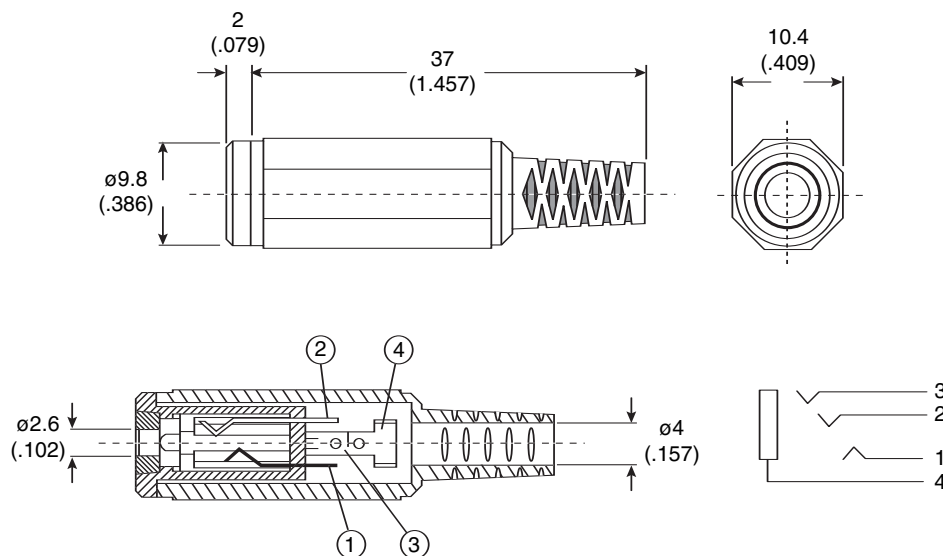

DIMENSIONS: mm (In.)

SPECIFICATIONS	
Dielectric strength:	500V AC for one minute
Contact resistance:	50m Ω max.
Insulation resistance:	100M Ω min. at 500V DC
Cap:	PE
Body:	PA
Contacts:	nickel plated brass

Date Last Revised: 4-5-05

Available from Mouser Electronics
1-800-346-6873
www.mouser.com

KC-300419

161-6425