


DC Power Plugs



1710-2110, 1710-2112, 1710-2510, 1710-2511

DC Power Plugs

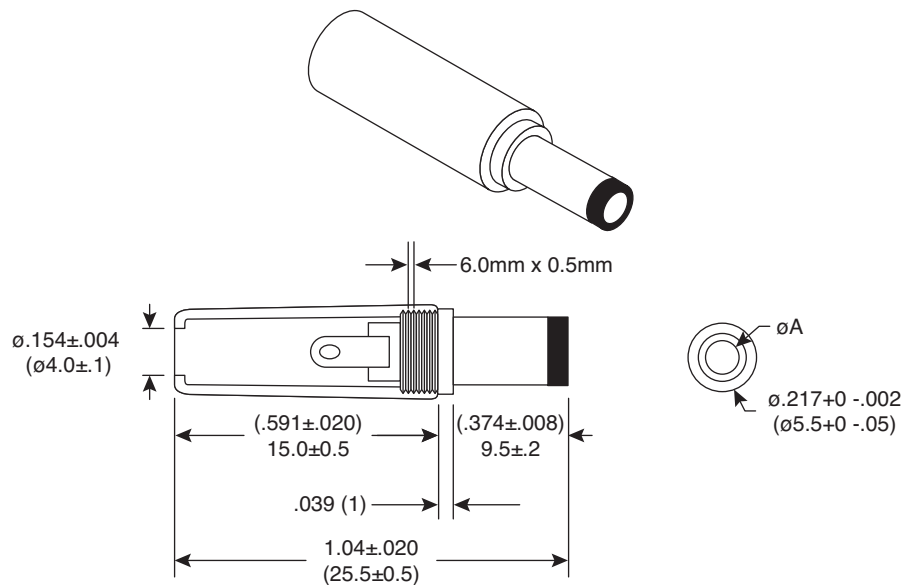

Dimensions: in. (mm)

SPECIFICATIONS	
Type:	DC Power
1710-2110 and 1710-2112 Dim. A:	.079 +.004/-.001" (2.0 +.1/-.03mm)
1710-2510 and 1710-2511 Dim. A:	.098 +.004/-.001" (2.5 +.1/-.03mm)
1710-2110 and 1710-2510 Handle Color:	Black
1710-2112 and 1710-2511 Handle Color:	Gray
Inner Barrel:	Copper
Outer Barrel, Terminals:	Nickel Plated Copper
Handle:	Phenolic Resin
Termianl Insulator:	Plastic
Maximum Amp:	1.5
Maximum Voltage (V):	24
Solder Temperature:	200°C for 3 seconds
Ambient Temperature:	-10°C to 50°C
Heat Deflection:	200°C

Date Last Revised: 9-10-12

Available from Mouser Electronics
1-800-346-6873 / www.mouser.com

KC-300473

Specifications are subject to change without notice. No liability or warranty implied by this information. Environmental compliance based on producer documentation.

1710-2110, 1710-2112, 1710-2510, 1710-2511