


Phone Jack

161-3551

KOBI CONN

Phone Jack

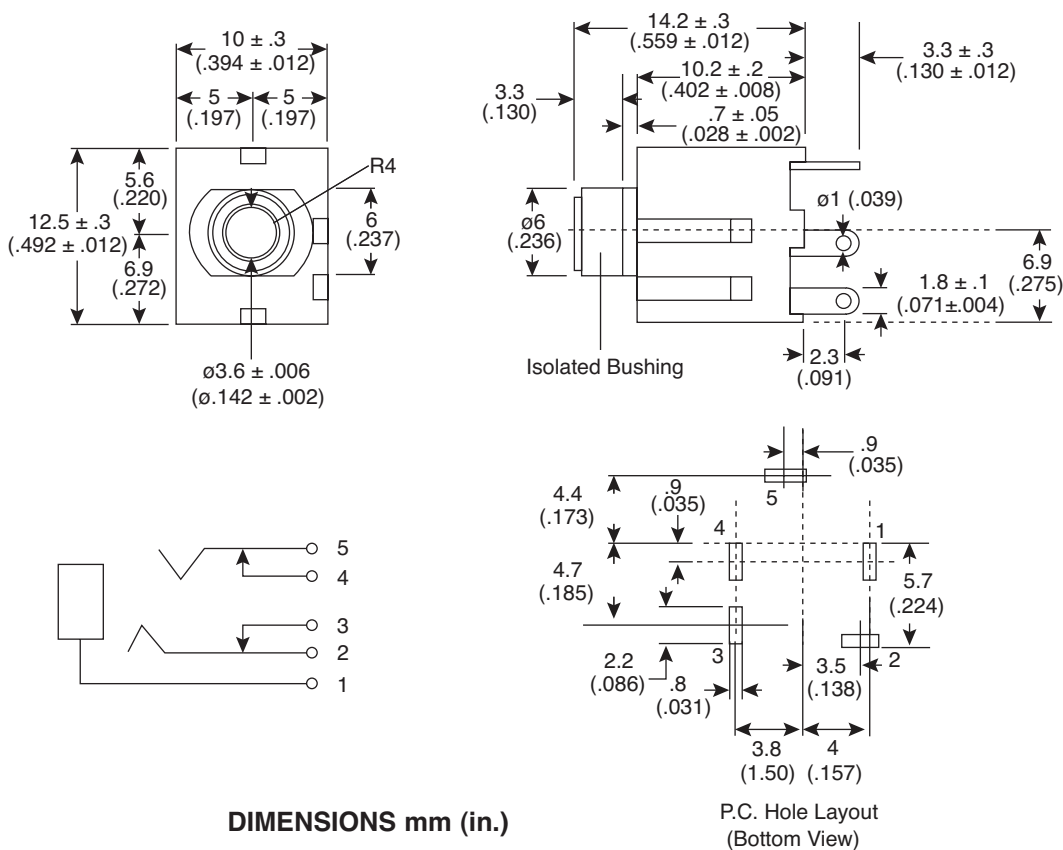

DIMENSIONS mm (in.)

P.C. Hole Layout
(Bottom View)

SPECIFICATIONS

Dielectric Strength:	250VAC for 1 minute
Insulation Resistance:	50MΩ min. @ 250VDC
Contact Resistance:	50mΩ max.
Operating Life:	10,000 cycles min.
Operating Temperature:	-10°~+70°C
Soldering Heat Test:	Solder Temperature: 260°C ±5°C
Dip Time:	5±1 seconds
Body Material:	Polycarbonate glass fiber 15%, black

Date Last Revised: 03-04-08

Available from Mouser Electronics
1-800-346-6873 / www.mouser.com

KC-300493

Specifications are subject to change without notice. No liability or warranty implied by this information. Environmental compliance based on producer documentation.

161-3551