
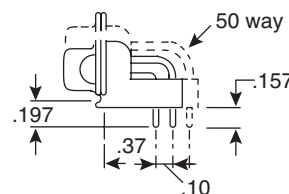
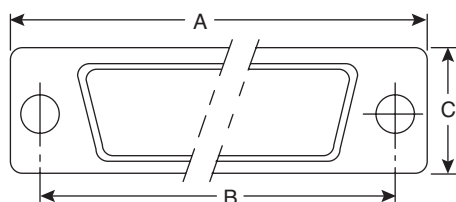
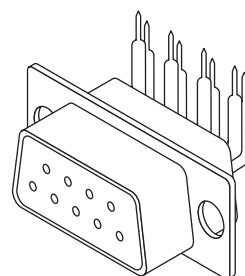
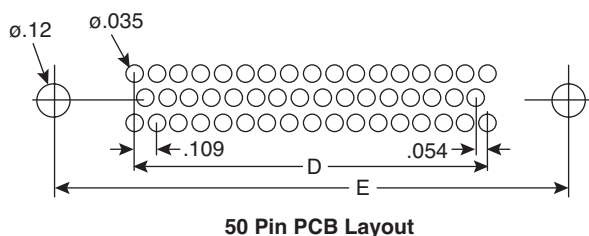
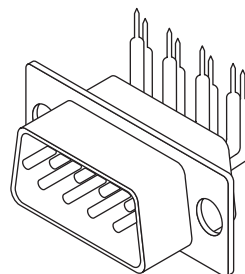


D-Sub Connectors with R/A PC Pins

152-5609, 152-5615, 152-5625, 152-5637, 152-5650,
152-5709, 152-5715, 152-5725, 152-5737, 152-5750

KOBICONN

D-Sub Connectors with R/A PC Pins

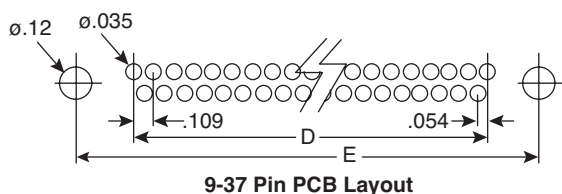

Dimensions: In.

Mouser Stock No.	Type	No. of Contacts	Dimensions (In.)				
			A	B	C	D	E
152-5609	Plug	9	1.213	.984	.488	.431	.984
152-5709	Receptacle	9	1.213	.984	.488	.431	.984
152-5615	Plug	15	1.543	1.311	.488	.755	1.311
152-5715	Receptacle	15	1.543	1.311	.488	.755	1.311
152-5625	Plug	25	2.091	1.850	.488	1.304	1.852
152-5725	Receptacle	25	2.091	1.850	.488	1.304	1.852
152-5637	Plug	37	2.736	2.500	.488	1.956	2.500
152-5737	Receptacle	37	2.736	2.500	.488	1.956	2.500
152-5650	Plug	50	2.638	2.406	.606	1.739	2.406
152-5750	Receptacle	50	2.638	2.406	.606	1.739	2.406

SPECIFICATIONS	
Rating:	5A/500VAC or DC Peak max.
Temperature Rating:	-55°C to +125°C
Contact Resistance:	5mΩ
Insulation Resistance:	10MΩ
Polarization:	By Trapezoidal Shell

MATERIALS	
Shell:	3~5μ" Zinc Plating over Yellow Chromate
Insulator:	Polyester, 30% Glass Filled, Gray
Contacts:	Copper Alloy, Gold Plated over Nickel
Wire:	20AWG max.

Date Last Revised: 10-18-05

Available from Mouser Electronics
1-800-346-6873
www.mouser.com

KC-300657