


PCB DIN Receptacle

161-0505

KOBICONN

PCB DIN Receptacles

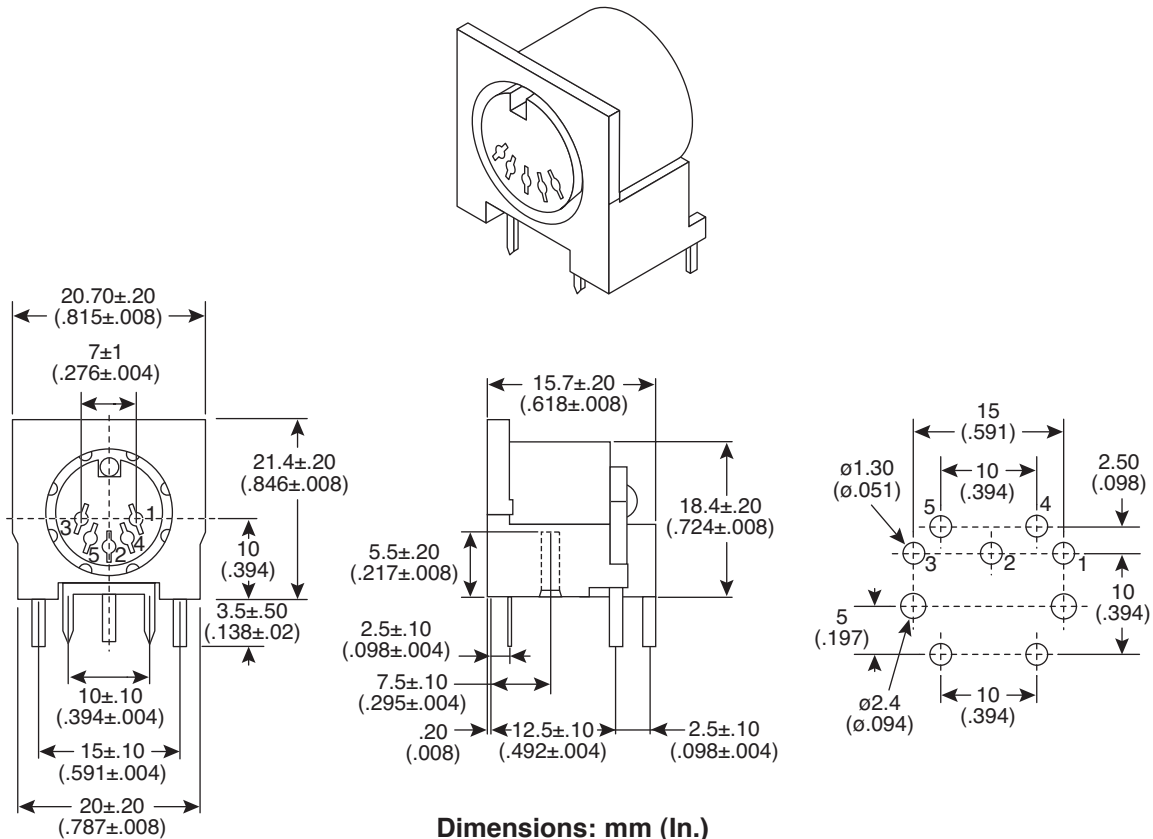

SPECIFICATIONS

Type:	PCB Mount DIN, Shielded
Rating:	2A/100VAC, 1A/24VDC
Contact Resistance:	20mΩ max.; <100mΩ After 5000 Cycles
Insulation Resistance:	100MΩ min. @ 500VDC
Dielectric Strength:	500VAC for 1 Minute
Insertion Force:	5.0Kg max.
Extraction Force:	1~3.5Kg
Mates With Plug ø:	.520±.008", .536±.004"
Dimension Tolerance:	±.008"
Marking:	U.E.C.
Body:	Valox 420-SEO with 30% Glass Fiber
Contact:	Tin Plated Brass
Insulator:	Bakelite
Shielding Terminal:	Tin Plated Phosphor Bronze

Date Last Revised: 10-18-05

Available from Mouser Electronics
1-800-346-6873
www.mouser.com

KC-300700

161-0505