


PLCC Sockets

151-1568, 151-1569

KOBICONN

PLCC Sockets

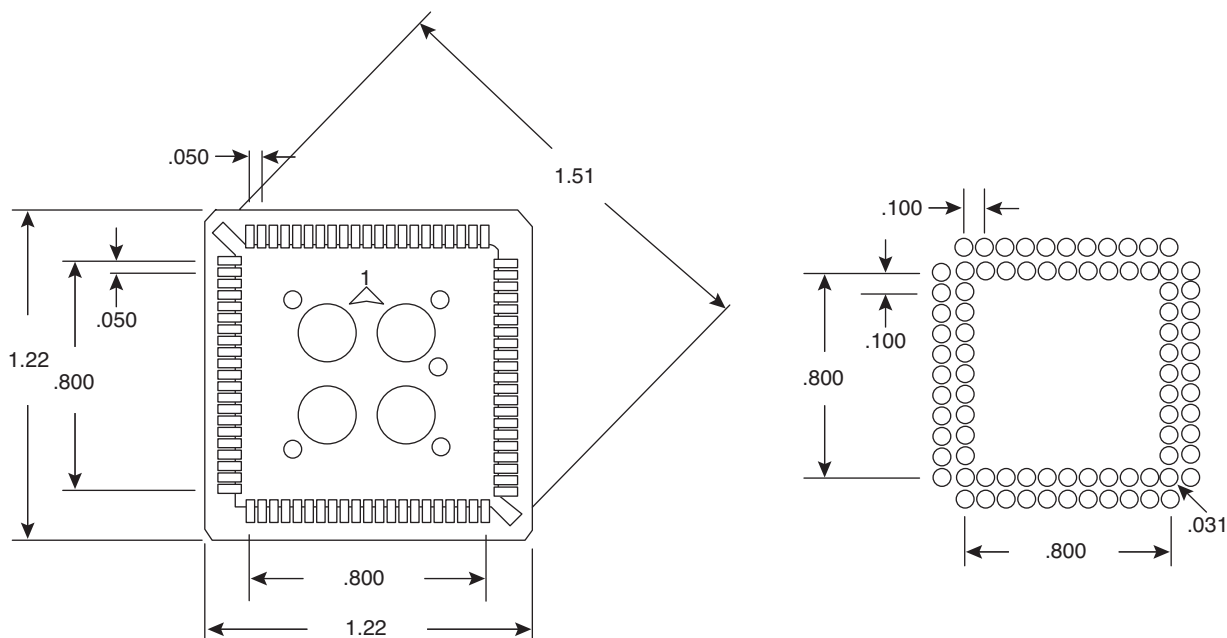

Dimensions: In.

SPECIFICATIONS

Type:	PLCC 68 pin, thru-hole
Contact resistance:	30mΩ max. @ 100mA DC
Insulator resistance:	1000MΩ min. @ 500VDC
Current rating:	1 amp
Voltage rating:	500VAC for 1 minute
Operating temperature:	-65°C to +125°C
Contact material:	plated phosphor bronze
Contact plating:	tin (151-1568); gold (151-1569)
Housing material:	PPS and 40% glass fiber

Date Last Revised: 10-18-05

Available from Mouser Electronics
1-800-346-6873
www.mouser.com

KC-300755

151-1568, 151-1569