


Terminal Blocks

158-P02142RPU, 158-P03142RPU, 158-P04142RPU, 158-P05142RPU,
158-P06142RPU, 158-P07142RPU, 158-P08142RPU, 158-P09142RPU,
158-P10142RPU, 158-P11142RPU, 158-P12142RPU

KOBI **CONN**

Terminal Blocks

158-P02142RPU, 158-P03142RPU, 158-P04142RPU, 158-P05142RPU, 158-P06142RPU, 158-P07142RPU, 158-P08142RPU, 158-P09142RPU, 158-P10142RPU, 158-P11142RPU, 158-P12142RPU

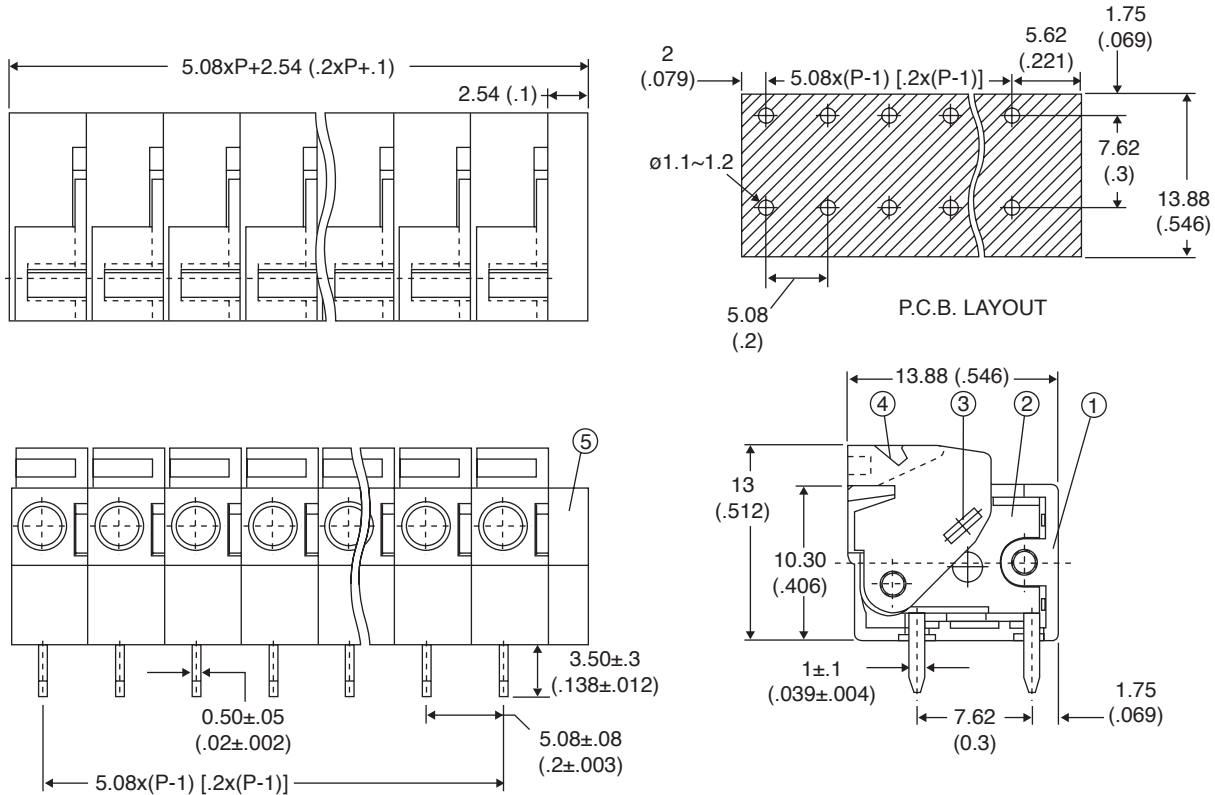

Dimensions: mm (In.)

ELECTRICAL SPECIFICATIONS

Rating:	300V 10A
Pitch:	5.08 mm
Insulation withstands voltage:	AC 1500V/Min
Insulation resistance:	500MΩ or more at DC500V
Temperature range:	-40°C~ +105°C
Electric wire:	22~14 AWG

MATERIAL SPECIFICATIONS

End Cover (5):	PA66, Green
Lever (4):	PA66, Orange
Clamping (3):	Stainless Steel
Solder Pin (2):	Copper, Tin Plated
Housing (1):	PA66, Green

Date Last Revised: 10-18-05

Available from Mouser Electronics
1-800-346-6873
www.mouser.com

KC- 300765