


Terminal Block Plugs

158-P02EC381VP Series



Terminal Block Plugs

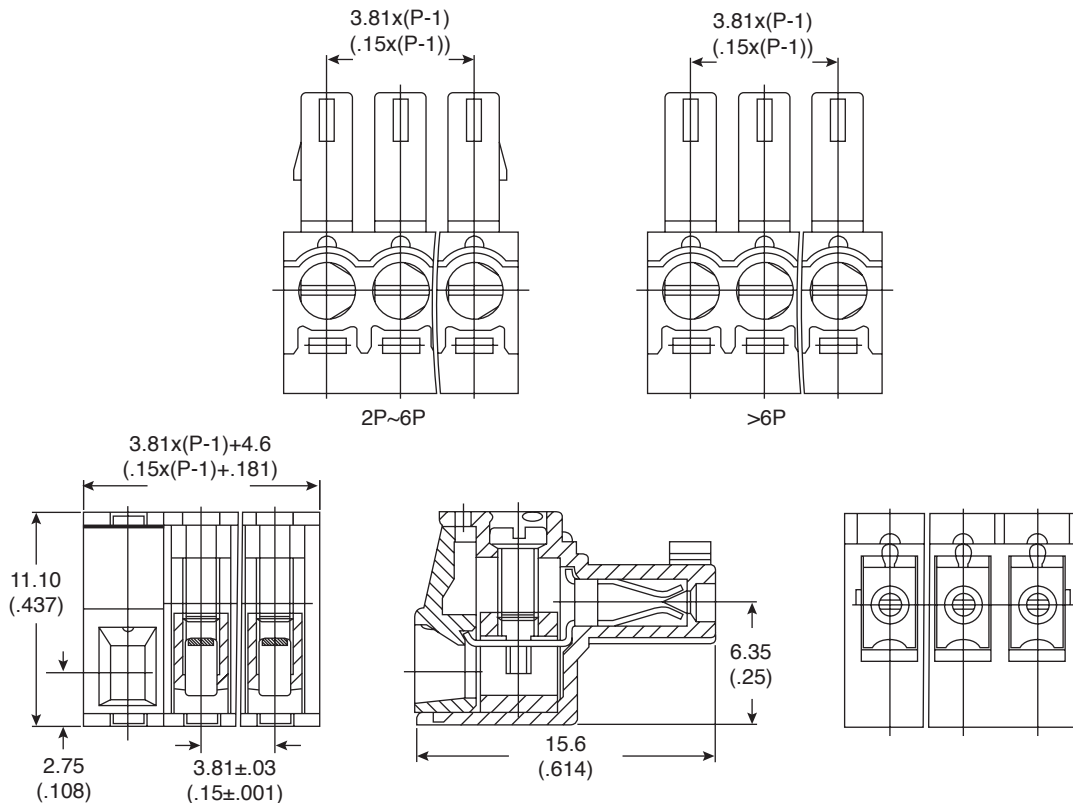

Dimensions: mm (In.)

ELECTRICAL SPECIFICATIONS

Rating:	300V 8A
Pitch:	3.81 mm
Insulation withstands voltage:	AC 1000V/Min
Insulation resistance:	1000MΩ or more at DC500V
Temperature range:	-40°C~ +120°C
Screw torque value:	2kg-cm(MAX)
Electric wire:	22~16 AWG

MATERIAL SPECIFICATIONS

Clamp:	bronze
Screw1:	steel, M2/Zn plated
End cover:	PBT, green
Wire cage:	hard brass M2/Ni plated
Housing:	PBT, green

Date Last Revised: 6-27-05

Available from Mouser Electronics
1-800-346-6873
www.mouser.com

KC- 300767

158-P02EC381VP Series