


Terminal Block Headers

158-P025EHDRCH, 158-P035EHDRCH, 158-P045EHDRCH, 158-P055EHDRCH,
158-P065EHDRCH, 158-P075EHDRCH, 158-P085EHDRCH, 158-P095EHDRCH,
158-P105EHDRCH, 158-P115EHDRCH, 158-P125EHDRCH

KOBI **CONN**

Terminal Block Headers

158-P025EHDRCH, 158-P035EHDRCH, 158-P045EHDRCH, 158-P055EHDRCH, 158-P065EHDRCH, 158-P075EHDRCH,
158-P085EHDRCH, 158-P095EHDRCH, 158-P105EHDRCH, 158-P115EHDRCH, 158-P125EHDRCH

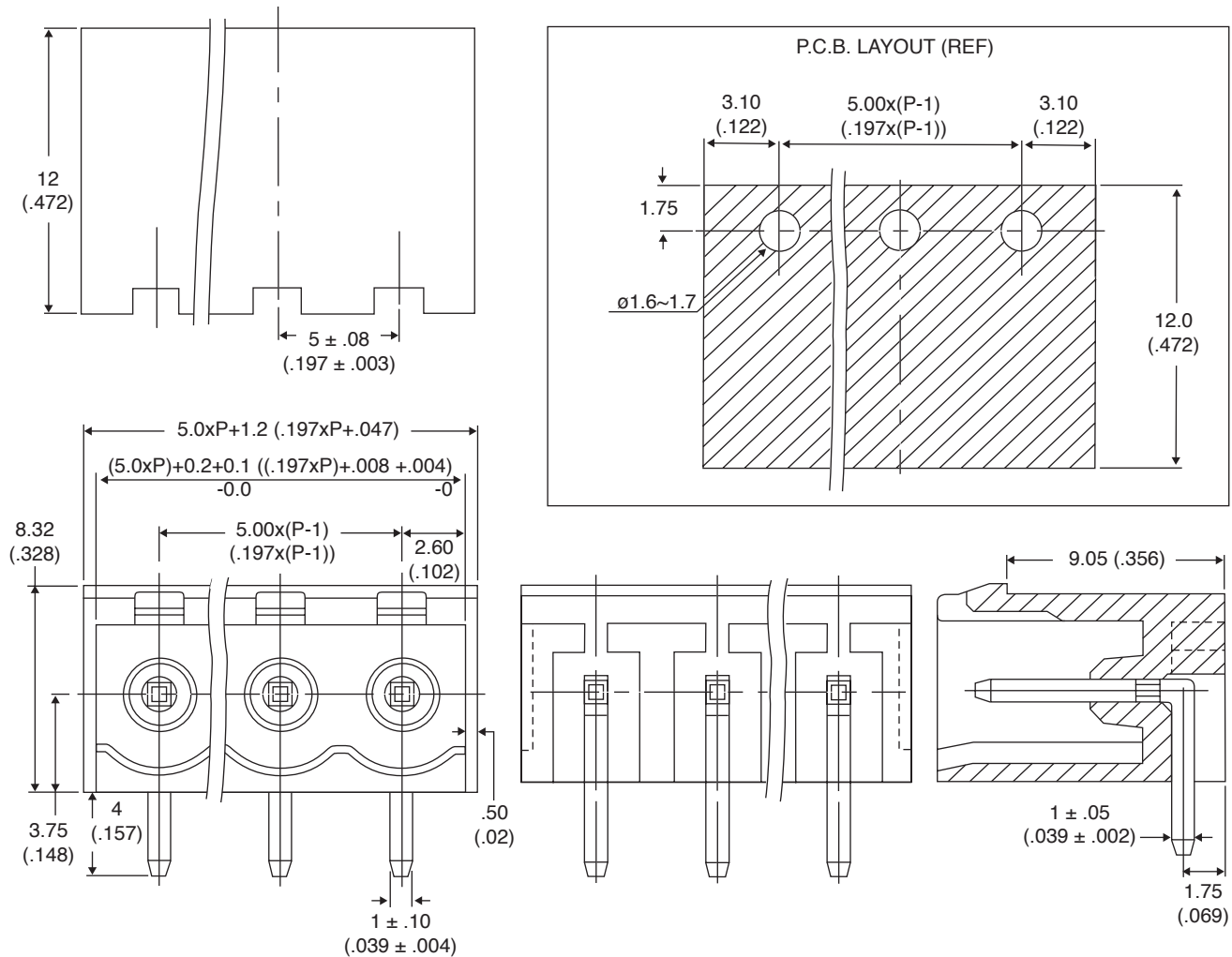

Dimensions: mm (In.)

SPECIFICATIONS

Rating:	300V 15A
Pitch:	5.00 mm
Insulation withstands voltage:	AC 1500 V/min
Insulation resistance:	500MΩ or more at DC500V
Temperature range:	-40°C ~ +105°C

MATERIAL SPECIFICATIONS

Solder pin:	tin plated copper
Housing:	PA66, green

Date Last Revised: 10-18-05

Available from Mouser Electronics
1-800-346-6873
www.mouser.com

KC- 300776