
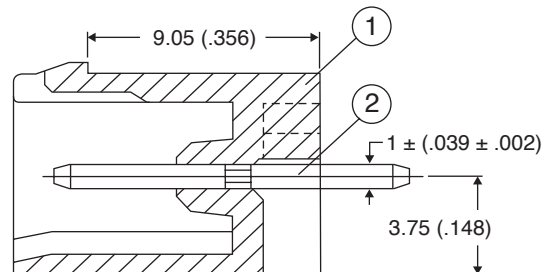
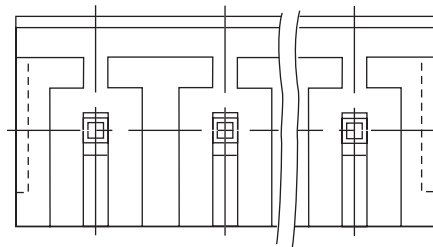
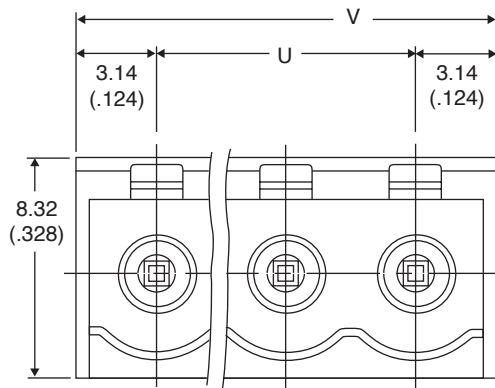
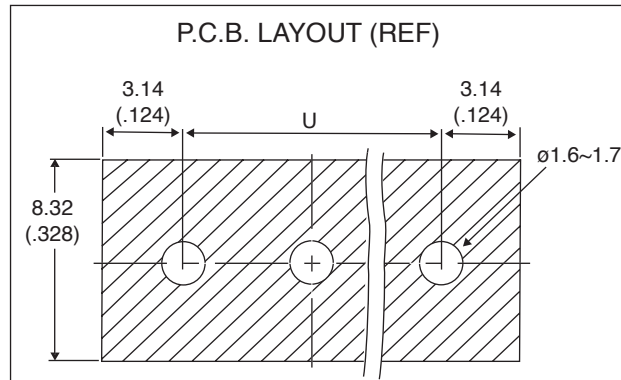


Terminal Block Headers

158-P022EHDVCH Series

KOBICONN

Terminal Block Headers

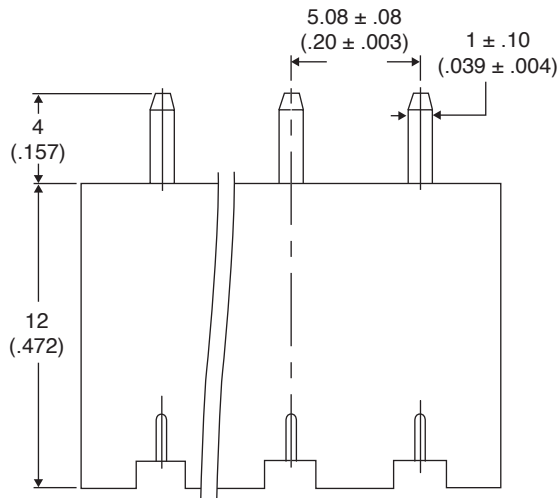

Dimensions: mm (In.)

P	02P	03P	04P	05P	06P	07P	08P	09P	10P	11P	12P
U mm	5.08	10.16	15.24	20.32	25.40	30.48	35.55	40.64	45.72	50.80	55.88
V mm	11.38	16.44	21.52	26.6	31.68	36.76	41.84	46.92	52.0	57.08	52.16

SPECIFICATIONS

Rating:	300V 15A
Pitch:	5.08 mm
Insulation withstands voltage:	AC 1500 V/min
Insulation resistance:	500MΩ or more at DC500V
Temperature range:	-40°C ~ +105°C

MATERIAL SPECIFICATIONS

2 Solder pin:	Copper tin plated
1 Housing:	PA66 green

Date Last Revised: 10/19/05

Available from Mouser Electronics
1-800-346-6873
www.mouser.com

KC- 300777

158-P022EHDVCH Series