


SMD Phone Jack

161-2623-E

KOBI CONN

SMD Phone Jack

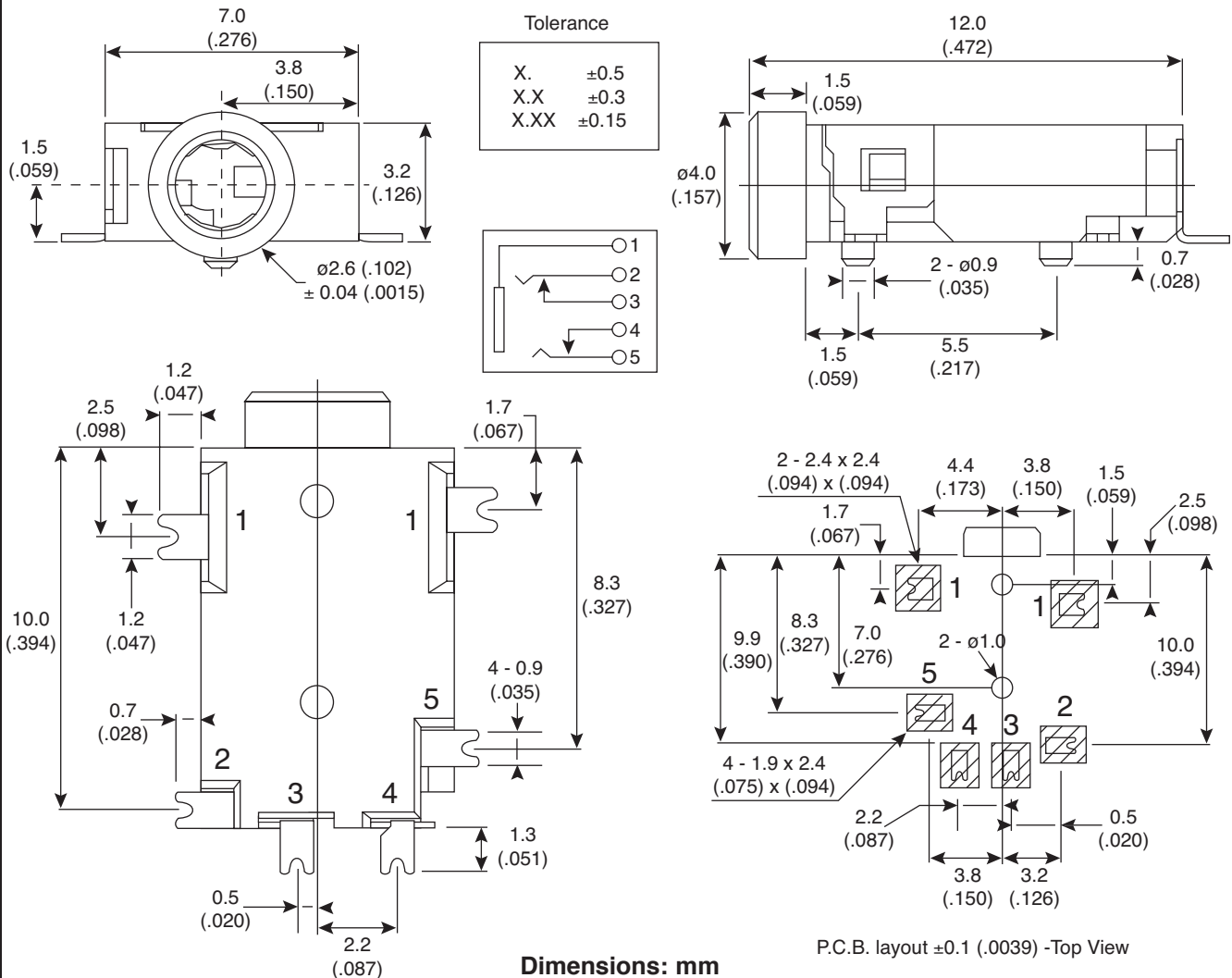

SPECIFICATIONS

Rating:	.3A 16VDC
Contact Resistance:	30 mΩ
Insulation Resistance	100 MΩ 500VDC
Dielectric Strength:	500VAC 1 min.

Material

Contacts:	Phosphor bronze
Housing:	Nylon-46 G30%
RoHS Compliant	

MECHANICAL

Durability:	5000 cycles
Insertion Force:	.3 Kg to 2.0 Kg
Extraction Force:	.2 Kg to 2.0 Kg
Soldering Temperature:	260°C for 5 seconds
Operating Temperature:	-25 to 80°C

Plating

Contacts:	Gold flash
------------------	------------

Date Last Revised: 6/26/12

Available from Mouser Electronics
1-800-346-6873
www.mouser.com

KC-300977

Specifications are subject to change without notice. No liability or warranty implied by this information. Environmental compliance based on producer documentation.

161-2623-E