
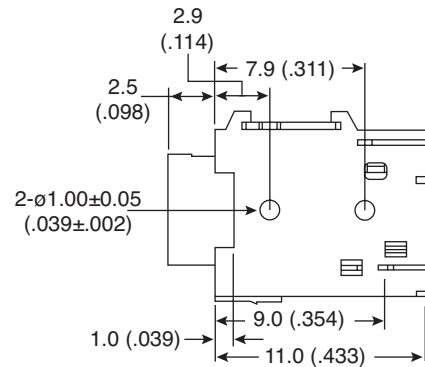
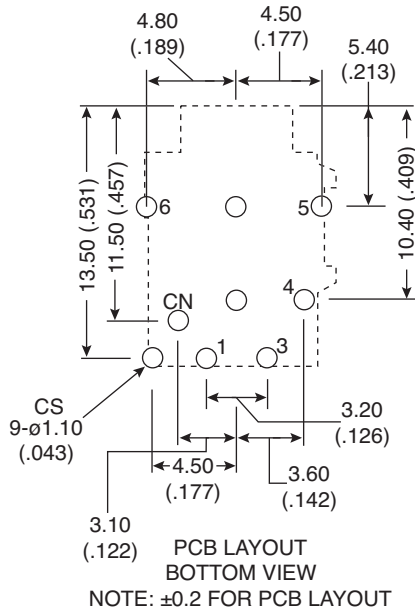
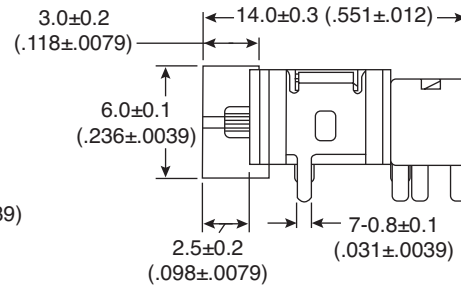


3.5mm 4 Pole Stereo Jack


161-5350-E

KOBICONN

3.5mm 4 Pole Stereo Jack

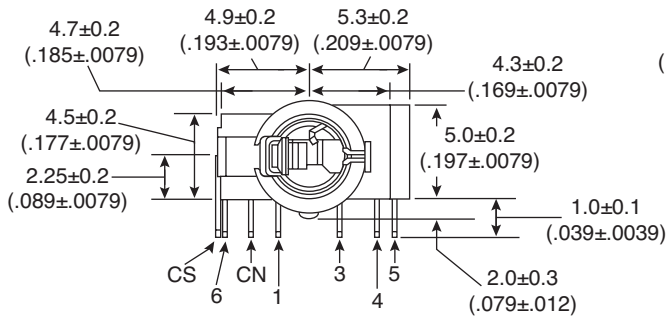

SCHEMATIC

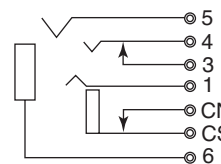

Dimensions: mm (in.)

SPECIFICATIONS

Housing:	PA66 Black
Terminals:	Phosphor bronze tin plated
Ground Terminal:	Phosphor bronze gold plated
Insertion/ Ext Force:	.3-3 Kgs
Dielectric Strength:	500 VAC for 1 min.
Insulation Resistance:	100 M ohm minimum
Contact Resistance:	50 m ohm maximum
Life Cycle:	5000 matings minimum
Operating Temperature:	-25°C to +85°C
Wave Soldering Temp:	265°C to $\pm 5^\circ\text{C}$ at 3 sec. ± 0.5 sec.
Voltage Rating:	16.0 VDC
Current Rating:	0.3 A
RoHS Compliant	

Date Last Revised: 03/08/07

Available from Mouser Electronics
1-800-346-6873 / www.mouser.com

KC-300985

Specifications are subject to change without notice. No liability or warranty implied by this information. Environmental compliance based on producer documentation.

161-5350-E