


DIMENSIONS: mm

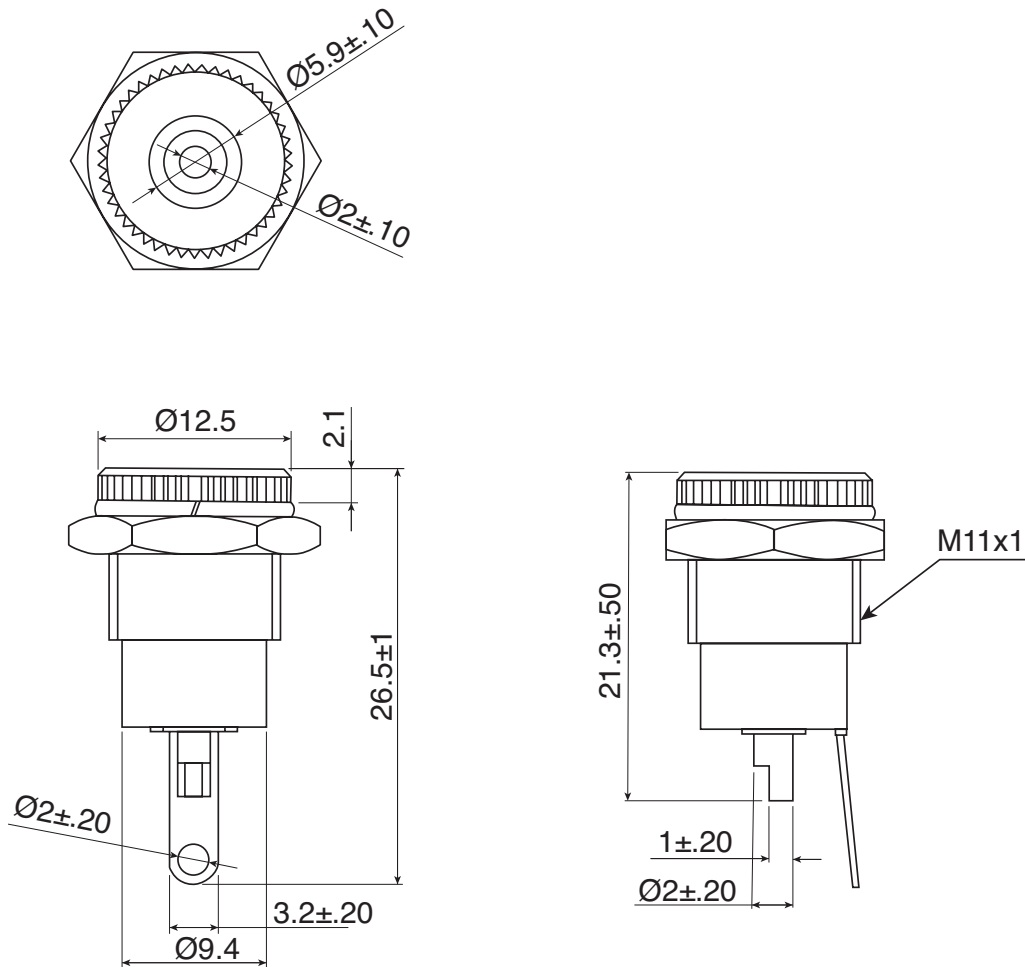

Specifications:

- Rating : 3A/125VAC/24VDC
- Insulation Resistance : 100M Ω @ 500VDC
- Dielectric Strength : 1000VAC for 1 minute
- Operation Temperature : -20°C~+80°C

Note: RoHS Compliant by Exemption

Available from Mouser Electronics
1-800-346-6873 / www.mouser.com

KC-301074