
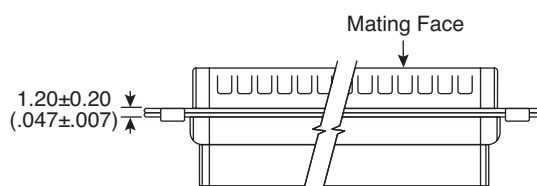
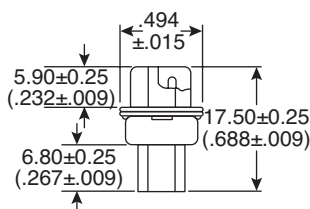
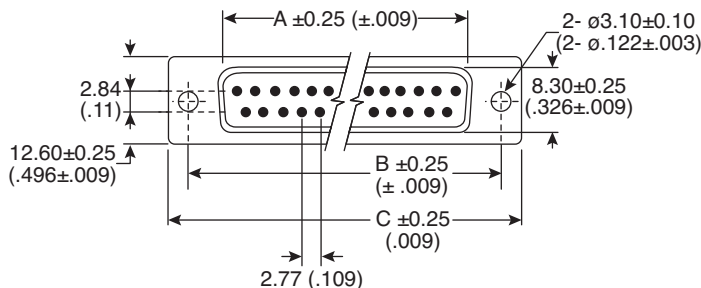


D-Sub Connector Crimp Housing Male

156-1410-E, 156-1416-E, 156-1426-E

KOBICONN

D-Sub Connector Crimp Housing Male

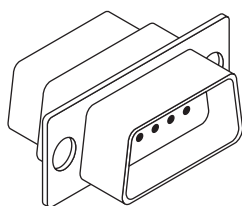

Dimensions: mm (in.)

MATERIAL SPECIFICATIONS

Front Insulator:	P.B.T. Black
Back Insulator:	PA66 Black
Contact:	Brass, t=0.20mm, Gold flashed
Shell:	Cold rolled steel, t=0.40mm Tin/Nickel/Zinc plated

ELECTRICAL SPECIFICATIONS

Current Rating:	1 A Max.
Dielectric Withstanding Voltage:	500 VAC for 1 minute
Contact Resistance:	30 mΩ Max.
Insulation Resistance:	1000 MΩ Min at DC 500V
Temperature Range:	-55°C~+105°C

RoHS Compliant

Mouser Stock No.	No. of Contacts	Dimensions: mm		
		A	B	C
156-1410-E	9	16.92	25.00	30.80
156-1416-E	15	25.25	33.32	39.20
156-1426-E	25	38.96	47.04	53.05

Date Last Revised: 9-11-07

Available from Mouser Electronics
1-800-346-6873 / www.mouser.com

KC-301178

Specifications are subject to change without notice. No liability or warranty implied by this information. Environmental compliance based on producer documentation.

156-1410-E, 156-1416-E, 156-1426-E