


IEC 60320 C14 Inlet

161-R301SN01-E

KOBICONN

IEC 60320 C14 Inlet

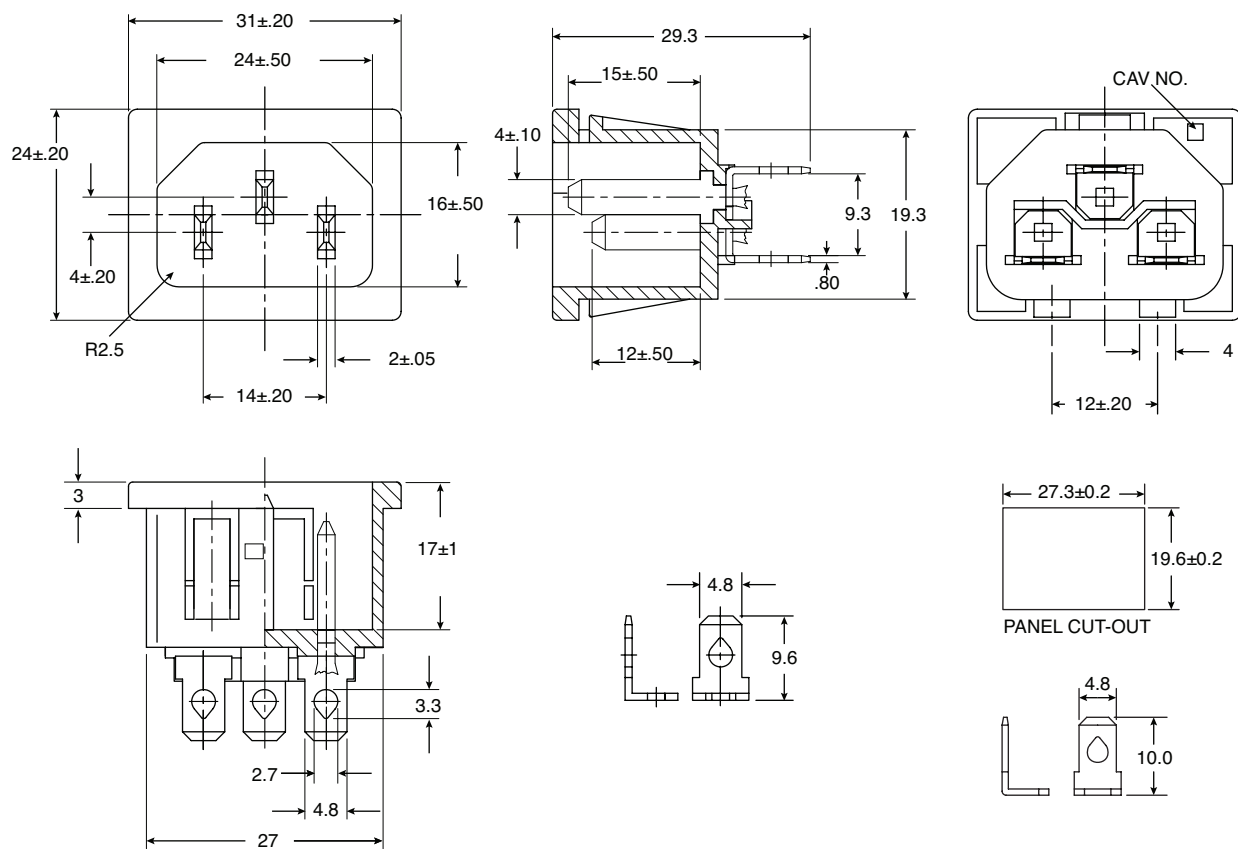

Dimensions: mm

SPECIFICATIONS

Rating:	15A, 250VAC
Insulation Resistance:	Over 100MΩ at 500VDC
Dielectric Strength:	2000VAC for 1 minute
Thickness:	1.5mm
RoHS Compliant	

Tolerance

X.XX±0.1
XX.XX±0.2
XXX.XX±0.3

Materials

Body: Nylon 66

Date Last Revised: 7-31-12

Available from Mouser Electronics
1-800-346-6873 / www.mouser.com

KC- 301184

Specifications are subject to change without notice. No liability or warranty implied by this information. Environmental compliance based on producer documentation.

161-R301SN01-E