
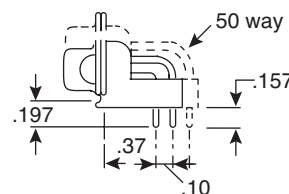
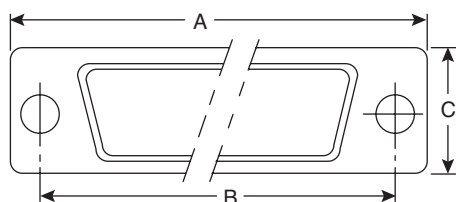
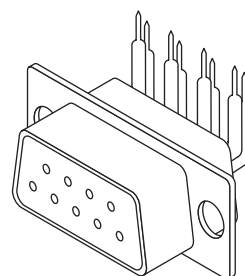
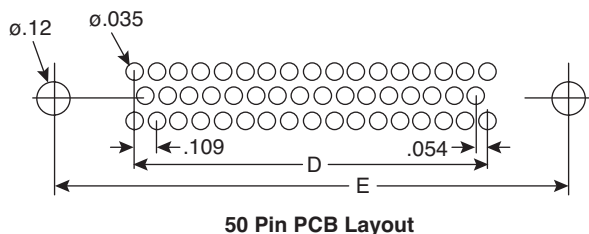
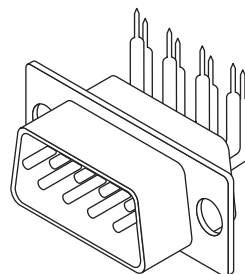


D-Sub Connectors with R/A PC Pins

152-5609-E, 152-5615-E, 152-5625-E, 152-5637-E,
152-5650-E, 152-5709-E, 152-5715-E, 152-5725-E,
152-5737-E, 152-5750-E

KOBICONN

D-Sub Connectors with R/A PC Pins

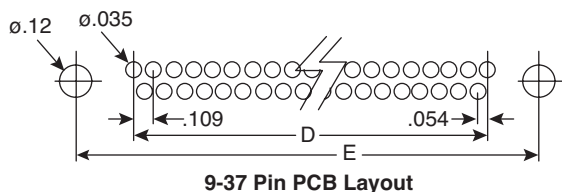

Dimensions: in.

Mouser Stock No.	Type	No. of Contacts	Dimensions (In.)				
			A	B	C	D	E
152-5609-E	Plug	9	1.213	.984	.488	.431	.984
152-5709-E	Receptacle	9	1.213	.984	.488	.431	.984
152-5615-E	Plug	15	1.543	1.311	.488	.755	1.311
152-5715-E	Receptacle	15	1.543	1.311	.488	.755	1.311
152-5625-E	Plug	25	2.091	1.850	.488	1.304	1.852
152-5725-E	Receptacle	25	2.091	1.850	.488	1.304	1.852
152-5637-E	Plug	37	2.736	2.500	.488	1.956	2.500
152-5737-E	Receptacle	37	2.736	2.500	.488	1.956	2.500
152-5650-E	Plug	50	2.638	2.406	.606	1.739	2.406
152-5750-E	Receptacle	50	2.638	2.406	.606	1.739	2.406

RoHS Compliant

SPECIFICATIONS

Rating:	5A/500VAC or DC Peak max.
Temperature Rating:	-55°C to +125°C
Contact Resistance:	5mΩ
Insulation Resistance:	10MΩ
Polarization:	By Trapezoidal Shell

MATERIALS

Shell:	3~5μ" Zinc Plating over Yellow Chromate
Insulator:	Polyester, 30% Glass Filled, Gray
Contacts:	Copper Alloy, Gold Plated over Nickel
Wire:	20AWG max.

Date Last Revised: 01-24-08

Available from Mouser Electronics
1-800-346-6873 / www.mouser.com

KC-301227

Specifications are subject to change without notice. No liability or warranty implied by this information. Environmental compliance based on producer documentation.

152-5609-E, 152-5615-E, 152-5625-E, 152-5637-E, 152-5650-E,
152-5709-E, 152-5715-E, 152-5725-E, 152-5737-E, 152-5750-E