


HDMI Receptacle, Type A Right Angle SMT

154-10428-E

KOBICONN

HDMI Receptacle, Type A Right Angle SMT

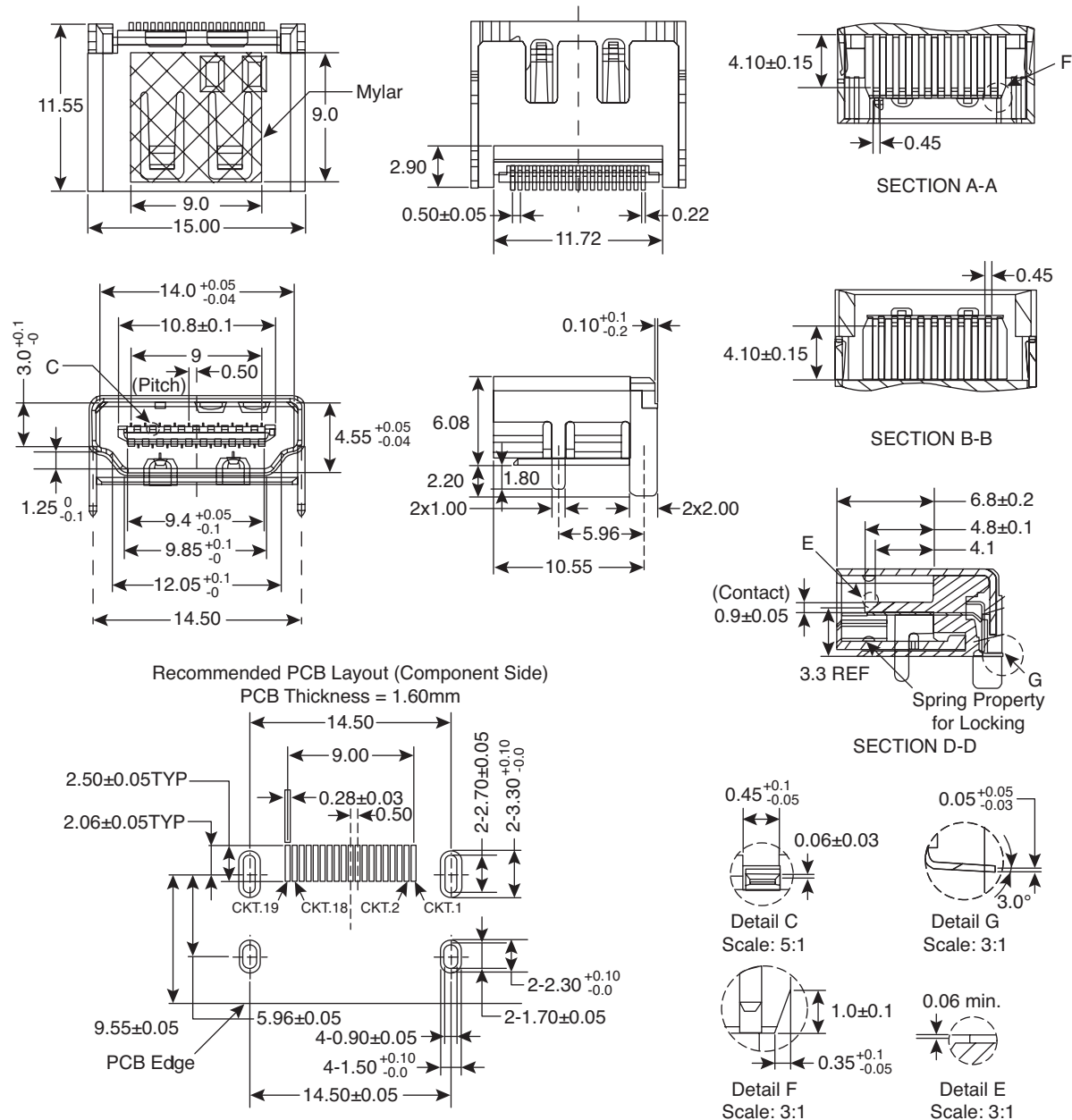

SPECIFICATIONS

Current Rating:	0.5A AC/DC
Voltage Rating:	40V AC/DC
Contact Resistance:	30MΩ MAX
Insulation Resistance:	100MΩ MIN.
Dielectric Withstanding Voltage:	500V AC/Minute

RoHS Compliant

MATERIALS

Housing:	LCP
Terminal:	Copper Alloy
Terminal Plating:	Gold 30 on contact and tin 100 on solder, all over nickel 80
Shell:	Copper Alloy
Shell Plating:	Tin 100 on solder, all over nickel 80

RoHS Compliant

Date Last Revised: 6/13/12

Available from Mouser Electronics
1-800-346-6873 / www.mouser.com

KC-301232

Specifications are subject to change without notice. No liability or warranty implied by this information. Environmental compliance based on producer documentation.

154-10428-E