
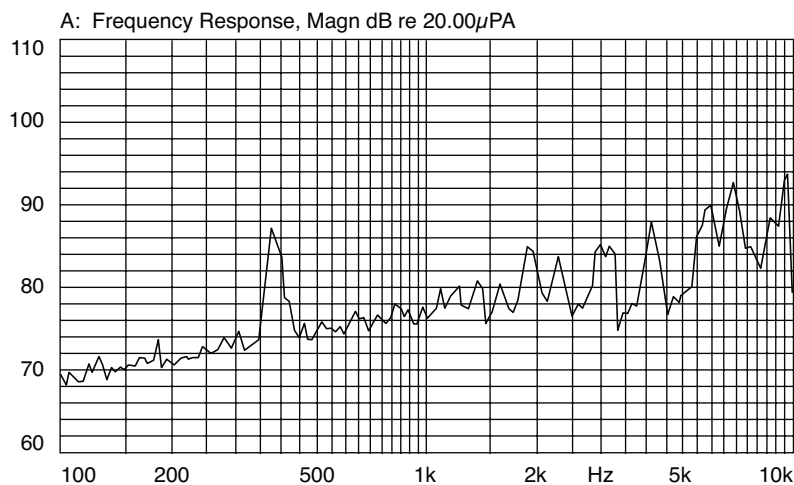


Part Number:

254-PB102-ROX

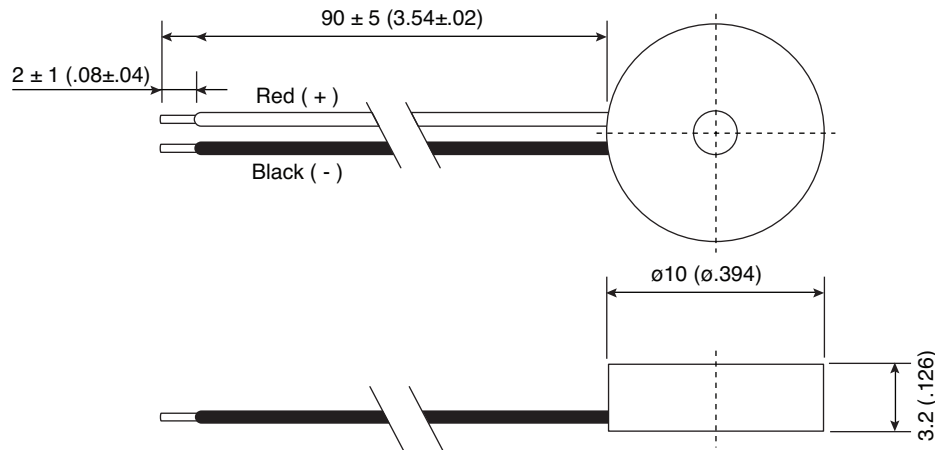

KT-400365

Electrical Specifications:

- Rated Voltage: 10 Vp-p
- Operating Voltage: 1~30 Vp-p
- Rated Current: 5mA(max)
- Sound Output at 10cm: 80dBA(min)
- Resonant Frequency: 3200Hz
- Capacitance: 11000pF ± 30% At 120Hz

Mechanical Specifications:

- Operating Temperature: -20°C ~ +60°C
- Storage Temperature: -20°C ~ +70°C

Note:

- RoHS Compliant by Exemption