


Part Number:

254-FP270-RO

Electret Condenser Microphone

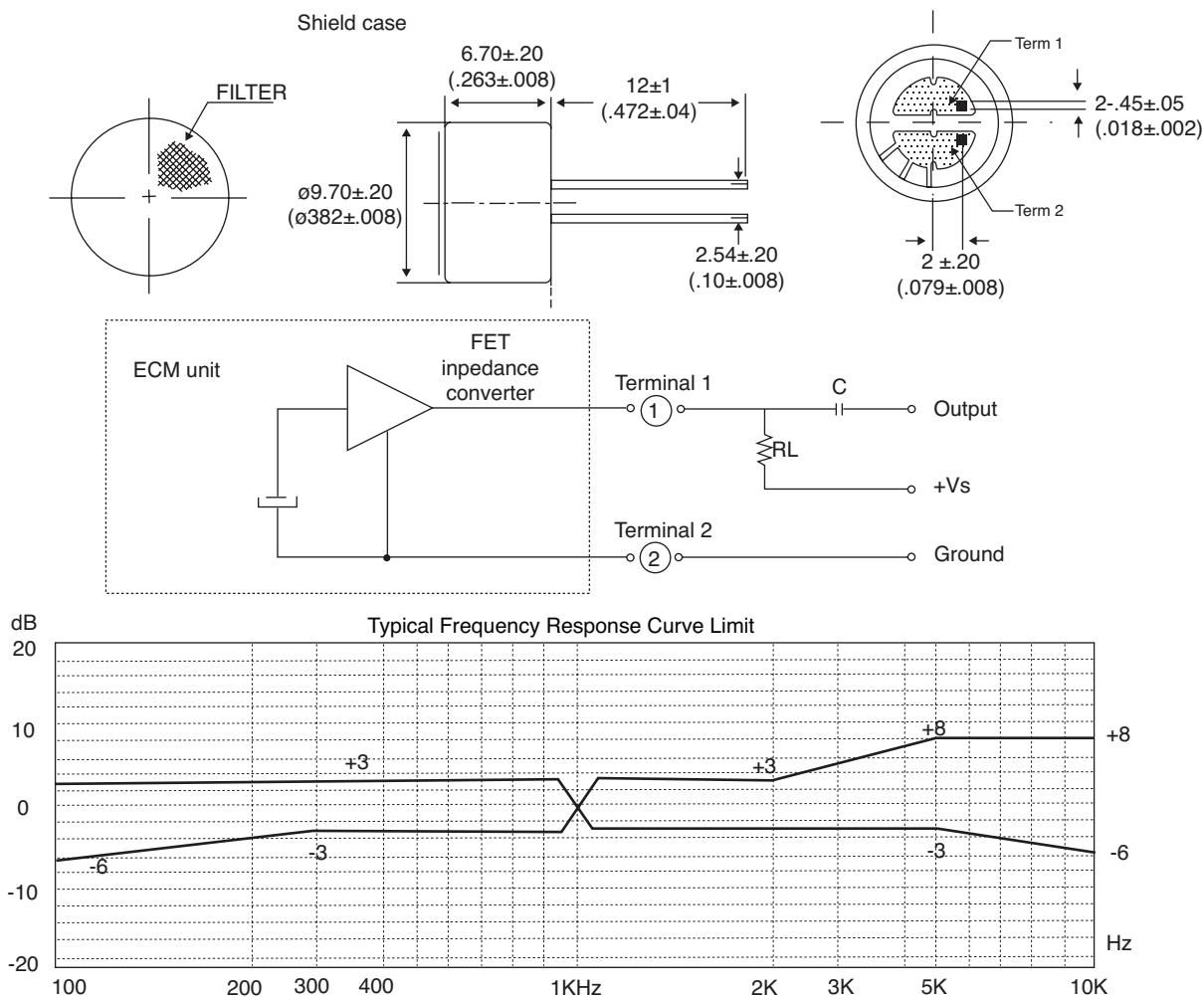

KT-400291

Electrical Specifications:

- Frequency: 50~16,000KHz
- Sensitivity: - 43dB min.
- Operating Voltage: 1.0V-10V
- Current Consumption: 500 μ A
- Output Impedance: 2.2k Ω @ f=1kHz,
- S/N Ratio: 60dB

Mechanical Specifications:

- Storage Temperature: 25°C ~ +70°C
- Operating Temperature: 20°C-- +60°

Note:

- RoHS Compliant